

Threaded locking clamp

Sta Stock

MBF

Quick and easy mounting

- Hexagonal headed sleeve for quickly fastening a shaft
- By tightening the sleeve with a spanner, a shaft can be fixed in any required position
- Smooth bore
- Material:
303/304 stainless steel

Application


- Supporting sensors, connecting tubes when assembling small structures

Accessories

- To be used with APBC rods, NSP, NSU or NSD support clamps or NRV and NRR joints



Suitable for food industry use

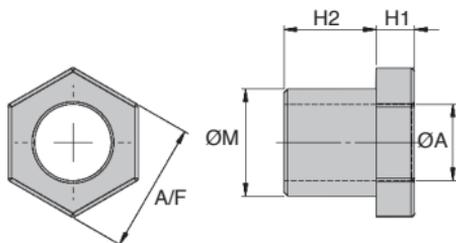

DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	For rod ØA	Ext thread ØM	H1	H2	Across flat A/F	Stock*	Price each 1 to 4
MBF8-12	8	M12x1,5	5	12	15	✓	4,94 €
MBF10-14	10	M14x1,5	5	12	17	✓	5,16 €
MBF12-16	12	M16x1,5	6	12	19	✓	5,47 €

Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



M1

Worm, Non hardened steel



HSE-HSB

Hexagonal spacer, Brass



KSM

Cylindrical steel nut, Steel - 1 thread



TSRTC

Stem support for caster, For swivel caster with central hole



PLA

Flat magnet, Flat magnet with thread



ALIDRP240

24V DC power supply, 10 A



LWH

High rigidity linear slide, Rail - from 9320 N to 71300 N



DOG111

Motor-gearbox 12V and 24V DC, from 1.5 to 6 Nm



PSPT

Flexible tube handle, PVC



PAS

Pull handle, Reinforced PA thermoplastic



ESCON

Speed controller 5A, 5 A



LRX

Linear roller slide, Rail - from 9410 N to 101000 N

Complementary products



APBC

Circular rod, Round rod



NSP

Right angled support clamp, Right angled support clamp