

# Threaded locking clamp

Sta Stock

MBF

Quick and easy mounting

- Hexagonal headed sleeve for quickly fastening a shaft
- By tightening the sleeve with a spanner, a shaft can be fixed in any required position
- Smooth bore
- Material:  
303/304 stainless steel

## Application


- Supporting sensors, connecting tubes when assembling small structures

## Accessories

- To be used with **APBC** rods, **NSP**, **NSU** or **NSD** support clamps or **NRV** and **NR** joints



Suitable for food industry use

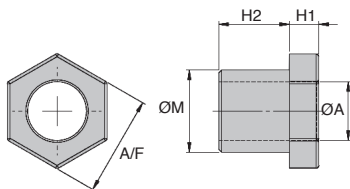

## DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	For rod ØA	Ext thread ØM	H1	H2	Across flat A/F	Stock*	Price each 1 to 4
MBF8-12	8	M12x1,5	5	12	15	✓	4,94 €
MBF10-14	10	M14x1,5	5	12	17	✓	5,16 €
MBF12-16	12	M16x1,5	6	12	19	✓	5,47 €

Depending on availability - Dimensions in mm

## Our other products



BAN  
Angular clamp,  
Adjustable



PR125rehausse  
Extension for  
articulated foot Ø123,  
articulated foot PR125




PR40  
Articulated foot Ø40,  
Ø 40



PRF\_FIX\_UNI  
Universal fastener for  
aluminium profile,  
Universal



BOXbeta  
Box of assorted hitch  
pins, Boxed set - hitch

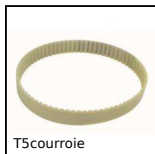

T5courroie  
T type timing belt, T5  
Steel cored  
polyurethane



PCS8ECO  
Chain sprocket - steel,  
8mm (DIN 05B-1)



CFF  
Female rod ends DIN  
ISO12240-4, Steel /  
bronze



UCF  
Cast iron flange  
bearing unit, Cast iron



RFVfp  
Stainless steel worm  
and wheel gearboxes,  
Mounting bracket




NDS20  
Double cross clamp,  
Parallel



H2  
Crossed helical gear  
crossed axis at 90°,  
Machined plastic  
(delrin)

## Complementary products

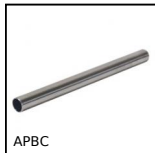

APBC  
Circular rod, Round  
rod



NSP  
Right angled support  
clamp, Right angled  
support clamp