

Threaded locking clamp

Sta Stock

MBF

Quick and easy mounting

- Hexagonal headed sleeve for quickly fastening a shaft
- By tightening the sleeve with a spanner, a shaft can be fixed in any required position
- Smooth bore
- Material:
303/304 stainless steel

Application


- Supporting sensors, connecting tubes when assembling small structures

Accessories

- To be used with APBC rods, NSP, NSU or NSD support clamps or NRV and NRR joints



Suitable for food industry use

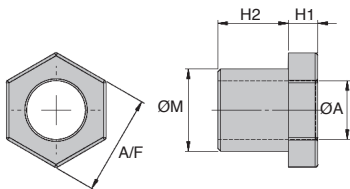

DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	For rod ØA	Ext thread ØM	H1	H2	Across flat A/F	Stock*	Price each 1 to 4
MBF8-12	8	M12x1,5	5	12	15	✓	4,94 €
MBF10-14	10	M14x1,5	5	12	17	✓	5,16 €
MBF12-16	12	M16x1,5	6	12	19	✓	5,47 €

Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



PW_PWG3
Wheel - precision range, Bronze



DOMI50
Accessories, Fixing kit



GPB
Threaded spherical knob, Moulded thread



BABFCFO
Ball pin socket, Mounting collar with a oval flange



 
MET
Cylindrical sintered bronze bush, Self-lubricating sintered bronze



PRT-TO
iglidur® slewing ring, With external teeth-Igclidur®, aluminium & S...



HCA
Magnetic screw with socket, Steel




GBMz
Cylindrical ballscrew nut, Cylindrical nut - Multiple starts



GLT3-46
Telescopic drawer,



 BLHM50
Right angled gearbox, double output shafts, up to 30 Nm



RPP5
RPP heavy duty timing belt, RPP5



EHD06
Internal epicyclic servo reducers, from 8 to 19 Nm

Complementary products



APBC
Circular rod, Round rod



NSP
Right angled support clamp, Right angled support clamp