

# Threaded locking clamp

Sta Stock

## MBF

## Quick and easy mounting

- Hexagonal headed sleeve for quickly fastening a shaft
- By tightening the sleeve with a spanner, a shaft can be fixed in any required position
- Smooth bore
- Material:  
303/304 stainless steel

### Application


- Supporting sensors, connecting tubes when assembling small structures

### Accessories

- To be used with APBC rods, NSP, NSU or NSD support clamps or NRV and NRR joints



Suitable for food industry use

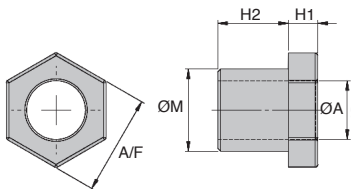

### DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	For rod ØA	Ext thread ØM	H1	H2	Across flat A/F	Stock*	Price each 1 to 4
MBF8-12	8	M12x1,5	5	12	15	✓	4,94 €
MBF10-14	10	M14x1,5	5	12	17	✓	5,16 €
MBF12-16	12	M16x1,5	6	12	19	✓	5,47 €

Depending on availability - Dimensions in mm

HPC

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

## Our other products



SER69K

Quarter turn latch for the food industry, Stainless steel



RFK48B

Hypoid gearbox - Stainless steel, up to 350 Nm




BH01

Single housed bearing, Bearing fitted with adhesive




PTCR

 Adjustable furniture foot, square tube



LAT2

 2A motorised linear actuator, 2 amperes



VP

Small 6 lobe threaded handle - male, Duroplast - Steel



SCA\_SS

Stainless steel flat cable clamp, Stainless steel



T5-BAR

T type tooth bar stock, T5




MHX

Hexagonal threaded sleeve, Hexagonal -



AT5P\_AT10P

Connecting plate for AT type timing belts,

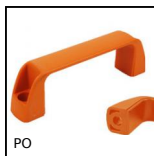

PO

Pull handle - Multi-sector, Smooth hole



EIM

Stainless steel U bolt, Stainless steel

## Complementary products



APBC

Circular rod, Round rod



NSP

Right angled support clamp, Right angled support clamp