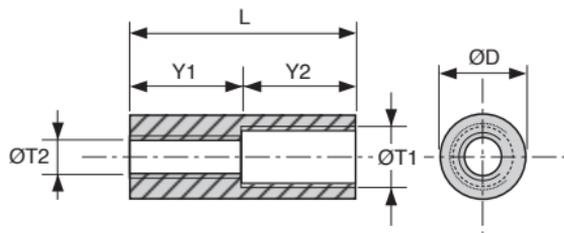


- Male/female sleeve
- Allows 2 rods of different diameters to be joined
- Materials:
 - Galvanised steel
 - 303 Stainless steel

Info.

- Supplied by pack

**DISCOUNTS**

Qty	1+	5+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	ØT1	ØT2	ØD	L	Y1	Y2	Qty per pack	Price each 1 to 4
Steel								
MCL6-8-40/B	M6	M8	13	40	20	20	20	24,89 €
MCL6-10-40/B	M6	M10	16	40	20	20	20	32,82 €
MCL8-10-40/B	M8	M10	16	40	20	20	20	32,82 €
MCL8-12-40/B	M8	M12	16	40	20	20	20	32,82 €
MCL10-12-40/B	M10	M12	16	40	20	20	20	32,82 €
MCL10-16-40/B	M10	M16	22	40	20	20	20	46,91 €
MCL12-16-40/B	M12	M16	22	40	20	20	20	46,91 €
Stainless steel								
MCL6-8-40/SS/B	M6	M8	13	40	20	20	20	56,27 €
MCL6-10-40/SS/B	M6	M10	16	40	20	20	20	74,27 €
MCL8-10-40/SS/B	M8	M10	16	40	20	20	20	74,27 €
MCL8-12-40/SS/B	M8	M12	16	40	20	20	20	74,27 €
MCL10-12-40/SS/B	M10	M12	16	40	20	20	20	74,27 €
MCL10-16-40/SS/B	M10	M16	22	40	20	20	20	137,37 €
MCL12-16-40/SS/B	M12	M16	22	40	20	20	20	137,37 €

Dimensions in mm

Cylindrical threaded sleeves




MCL

Steel or stainless steel

- Cylindrical sleeves, through threaded
- Suitable for joining threaded bars
- Materials:
Zn3-5BL galvanised steel S300PB
Stainless steel 303
- Sold by the packet

Steel or stainless steel

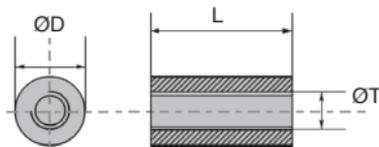

DISCOUNTS

No. packets	1+	5+	20+	50+
Discounts	List	-5%	-10%	On request

Part number		Thread				Qty per packet	Stock*		Price per packet 1 to 4	
Steel	Stainless steel	ØT	L	ØD	Steel		S/steel	Steel	S/steel	
MCL4-15/B	-	M4	15	7	20	✓	-	5,56 €	-	
MCL4-20/B	-	M4	20	7	20	✓	-	5,93 €	-	
-	MCL5-15/SS/B	M5	15	8	20	-	✓	-	20,40 €	
MCL5-20/B	-	M5	20	8	20	✓	-	4,93 €	-	
MCL5-25/B	-	M5	25	8	20	✓	-	5,33 €	-	
MCL6-10/B	MCL6-10/SS/B	M6	10	10	20	✓	✓	7,39 €	24,12 €	
MCL6-15/B	-	M6	15	10	20	✓	-	4,70 €	-	
MCL6-20/B	MCL6-20/SS/B	M6	20	10	20	✓	✓	5,14 €	31,62 €	
MCL6-25/B	MCL6-25/SS/B	M6	25	10	20	✓	✓	6,07 €	37,75 €	
MCL6-30/B	MCL6-30/SS/B	M6	30	10	20	✓	✓	7,63 €	44,93 €	
MCL6-35/B	-	M6	35	10	20	✓	-	9,13 €	-	
MCL6-40/B	-	M6	40	10	20	✓	-	11,27 €	-	
MCL6-50/B	-	M6	50	10	20	✓	-	16,36 €	-	
MCL8-15/B	-	M8	15	11	20	✓	-	4,75 €	-	
MCL8-20/B	MCL8-20/SS/B	M8	20	11	20	✓	✓	5,43 €	36,72 €	
MCL8-25/B	MCL8-25/SS/B	M8	25	11	20	✓	-	5,49 €	38,81 €	
MCL8-30/B	MCL8-30/SS/B	M8	30	11	20	✓	✓	6,63 €	47,95 €	
MCL8-35/B	MCL8-35/SS/B	M8	35	11	20	-	-	10,01 €	58,19 €	
MCL8-40/B	MCL8-40/SS/B	M8	40	11	20	✓	-	11,37 €	60,24 €	
MCL8-50/B	MCL8-50/SS/B	M8	50	11	20	✓	✓	16,50 €	73,51 €	
MCL10-20/B	MCL10-20/SS/B	M10	20	13	20	✓	-	7,39 €	45,95 €	
MCL10-25/B	MCL10-25/SS/B	M10	25	13	20	-	-	8,08 €	On request	
MCL10-30/B	MCL10-30/SS/B	M10	30	13	20	-	-	8,91 €	66,36 €	
MCL10-35/B	-	M10	35	13	20	-	-	10,65 €	-	
MCL10-40/B	MCL10-40/SS/B	M10	40	13	20	-	-	11,94 €	88,84 €	
MCL10-50/B	MCL10-50/SS/B	M10	50	13	20	-	-	19,91 €	100,08 €	
MCL10-60/B	-	M10	60	13	20	-	-	22,81 €	-	
MCL12-20/B	-	M12	20	15	20	✓	-	9,00 €	-	
MCL12-25/B	-	M12	25	15	20	-	-	10,89 €	-	
MCL12-30/B	MCL12-30/SS/B	M12	30	15	20	✓	-	11,92 €	88,84 €	
MCL12-35/B	-	M12	35	15	20	-	-	12,87 €	-	
MCL12-40/B	MCL12-40/SS/B	M12	40	15	20	-	-	14,97 €	102,15 €	
MCL12-50/B	MCL12-50/SS/B	M12	50	15	20	-	-	21,84 €	122,53 €	
MCL12-60/B	-	M12	60	15	20	✓	-	26,39 €	-	

*Depending of availability - Dimensions in mm