



Cylindrical reducing sleeve

SteSta

MCL

Steel or **stainless steel**

- **Male/female sleeve**
- Allows 2 rods of different diameters to be joined
- **Materials:**
 - Galvanised steel
 - 303 Stainless steel
- **Supplied by the pack**

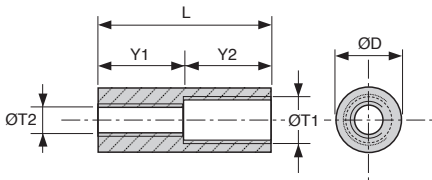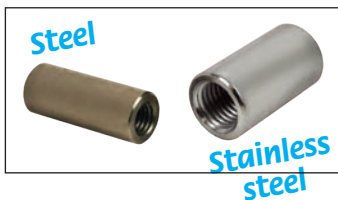

DISCOUNTS

Qty	1+	5+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	ØT1	ØT2	ØD	L	Y1	Y2	Qty per pack	Price each 1 to 4
Steel								
MCL6-8-40/B	M6	M8	13	40	20	20	20	19,82 €
MCL6-10-40/B	M6	M10	16	40	20	20	20	28,36 €
MCL8-10-40/B	M8	M10	16	40	20	20	20	28,36 €
MCL8-12-40/B	M8	M12	16	40	20	20	20	28,36 €
MCL10-12-40/B	M10	M12	16	40	20	20	20	28,36 €
MCL10-16-40/B	M10	M16	22	40	20	20	20	40,53 €
MCL12-16-40/B	M12	M16	22	40	20	20	20	40,53 €
Stainless steel								
MCL6-8-40/SS/B	M6	M8	13	40	20	20	20	53,60 €
MCL6-10-40/SS/B	M6	M10	16	40	20	20	20	70,75 €
MCL8-10-40/SS/B	M8	M10	16	40	20	20	20	70,75 €
MCL8-12-40/SS/B	M8	M12	16	40	20	20	20	70,75 €
MCL10-12-40/SS/B	M10	M12	16	40	20	20	20	70,75 €
MCL10-16-40/SS/B	M10	M16	22	40	20	20	20	130,85 €
MCL12-16-40/SS/B	M12	M16	22	40	20	20	20	130,85 €

Dimensions in mm

Our other products



DBC

Panamech, Multi-Beam, Aluminium - with clamping jaw



GCT

Pipe linch pin, Tube linch pin



H0

Crossed helical gear
crossed axis at 90°,
Steel 20NCD2



SH0

Parallel axis helical gear,
Machined plastic (delrin)



ASH

Hoist ring for welding,
for straight lifts - for
welding



PRF-GPA

Guide for aluminium
profile, Parallel rails




PT881

Drive sprocket for slat
top chain, Range 881




DOMI30

 Accessories, Turntable



QN

 Single row cylindrical
roller bearing, Free
outer ring



CFC

Spring loaded position
switch, Electric
contact



MSP23

Masterplate®
glueable insert Ø23,
Cylindrical Ø23 with



FDS

Flexible drive shaft,
Masterflex® Steel,
with PVC casing

Complementary products



MHXred

Reducing sleeve
male/female,
Hexagonal - stainless
steel



TIF

Threaded rod -
DIN975, Stainless
steel A2



TIFss

Threaded stud -
DIN976A, Stainless
steel



MCL

Cylindrical threaded
sleeve, Cylindrical -
stainless steel