


Cylindrical reducing sleeve

SteSta

MCL

Steel or **stainless steel**

- **Male/female sleeve**
- Allows 2 rods of different diameters to be joined
- **Materials:**
 - Galvanised steel
 - 303 Stainless steel
- **Supplied by the pack**

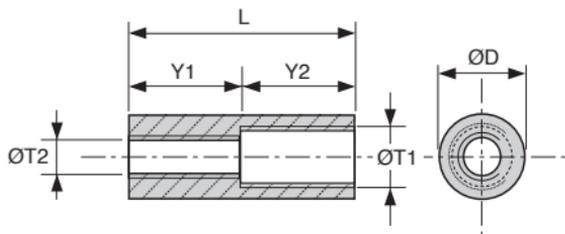


DISCOUNTS

Qty	1+	5+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	ØT1	ØT2	ØD	L	Y1	Y2	Qty per pack	Price each 1 to 4
Steel								
MCL6-8-40/B	M6	M8	13	40	20	20	20	19,82 €
MCL6-10-40/B	M6	M10	16	40	20	20	20	28,36 €
MCL8-10-40/B	M8	M10	16	40	20	20	20	28,36 €
MCL8-12-40/B	M8	M12	16	40	20	20	20	28,36 €
MCL10-12-40/B	M10	M12	16	40	20	20	20	28,36 €
MCL10-16-40/B	M10	M16	22	40	20	20	20	40,53 €
MCL12-16-40/B	M12	M16	22	40	20	20	20	40,53 €
Stainless steel								
MCL6-8-40/SS/B	M6	M8	13	40	20	20	20	53,60 €
MCL6-10-40/SS/B	M6	M10	16	40	20	20	20	70,75 €
MCL8-10-40/SS/B	M8	M10	16	40	20	20	20	70,75 €
MCL8-12-40/SS/B	M8	M12	16	40	20	20	20	70,75 €
MCL10-12-40/SS/B	M10	M12	16	40	20	20	20	70,75 €
MCL10-16-40/SS/B	M10	M16	22	40	20	20	20	130,85 €
MCL12-16-40/SS/B	M12	M16	22	40	20	20	20	130,85 €

Dimensions in mm

Our other products

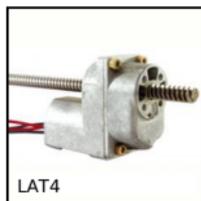

LAT4

4A motorised linear actuator, 4 amperes



AC144

Strike for toggle latch, 22mm



ACAss

Stainless steel splined shaft, Stainless steel



DIA

Ring operated locking bolt, with ring



NPTR10

Adjustable cross clamp, Adjustable




RAM35

Manual bevel gearbox, Bevel



BH01

Single housed bearing, Bearing fitted with adhesive

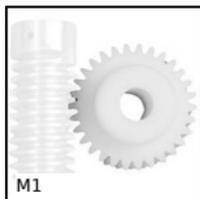

M1

Worm and wheel set, Machined plastic (delrin)



ZG125

Plastic spur gear, Machined plastic (delrin)



LRR

Catch-plate for latch, Catch-plate



PSG255

Spur gear - precision range, Stainless steel 316



VPRA_M

Handwheel with handle, Thermosetting plastic - galvanised steel hub

Complementary products



MHXred

Reducing sleeve male/female, Hexagonal - stainless steel



TIF

Threaded rod - DIN975, Stainless steel A2



TIFss

Threaded stud - DIN976A, Stainless steel



MCL

Cylindrical threaded sleeve, Cylindrical - stainless steel