


Cylindrical reducing sleeve

SteSta

MCL

Steel or **stainless steel**

- **Male/female sleeve**
- Allows 2 rods of different diameters to be joined
- **Materials:**
 - Galvanised steel
 - 303 Stainless steel
- **Supplied by the pack**

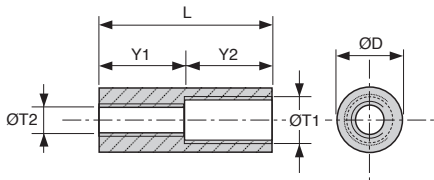

DISCOUNTS

Qty	1+	5+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	ØT1	ØT2	ØD	L	Y1	Y2	Qty per pack	Price each 1 to 4
Steel								
MCL6-8-40/B	M6	M8	13	40	20	20	20	19,82 €
MCL6-10-40/B	M6	M10	16	40	20	20	20	28,36 €
MCL8-10-40/B	M8	M10	16	40	20	20	20	28,36 €
MCL8-12-40/B	M8	M12	16	40	20	20	20	28,36 €
MCL10-12-40/B	M10	M12	16	40	20	20	20	28,36 €
MCL10-16-40/B	M10	M16	22	40	20	20	20	40,53 €
MCL12-16-40/B	M12	M16	22	40	20	20	20	40,53 €
Stainless steel								
MCL6-8-40/SS/B	M6	M8	13	40	20	20	20	53,60 €
MCL6-10-40/SS/B	M6	M10	16	40	20	20	20	70,75 €
MCL8-10-40/SS/B	M8	M10	16	40	20	20	20	70,75 €
MCL8-12-40/SS/B	M8	M12	16	40	20	20	20	70,75 €
MCL10-12-40/SS/B	M10	M12	16	40	20	20	20	70,75 €
MCL10-16-40/SS/B	M10	M16	22	40	20	20	20	130,85 €
MCL12-16-40/SS/B	M12	M16	22	40	20	20	20	130,85 €

Dimensions in mm

Our other products



VRSF

Male swivelling lifting ring, Male swivelling



GPB

Threaded spherical knob, With brass insert



T25-6ECO

T type timing pulley, Economy range - T2.5 aluminium



T5courroie

T type timing belt, T5 Steel cored polyurethane



J66

Spur gear coaxial gearbox, from 0.90 to 2.80 Nm - In-line



 
SHA_PTR

Handwheel with folding handle, Polyamide



DKONSL

Silicone conical elasto buffer, Male mounting



BETASS

Hitch pin, Hitch



SHTP

Drylin® Linear table, Economy range



PPF

Indexing plunger with flange, with drilled



ASH

Hoist ring for welding, for straight lifts - for



PW_PWG05

Worm - precision range, Stainless steel

Complementary products



MHXred

Reducing sleeve male/female, Hexagonal - stainless steel



TIF

Threaded rod - DIN975, Stainless steel A2



TIFss

Threaded stud - DIN976A, Stainless steel



MCL

Cylindrical threaded sleeve, Cylindrical - stainless steel