


Cylindrical reducing sleeve

SteSta

MCL

Steel or **stainless steel**

- **Male/female sleeve**
- Allows 2 rods of different diameters to be joined
- Materials:
 - Galvanised steel
 - 303 Stainless steel
- **Supplied by the pack**

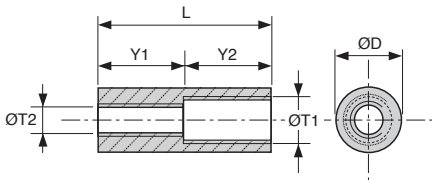


DISCOUNTS

Qty	1+	5+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	ØT1	ØT2	ØD	L	Y1	Y2	Qty per pack	Price each 1 to 4
Steel								
MCL6-8-40/B	M6	M8	13	40	20	20	20	19,82 €
MCL6-10-40/B	M6	M10	16	40	20	20	20	28,36 €
MCL8-10-40/B	M8	M10	16	40	20	20	20	28,36 €
MCL8-12-40/B	M8	M12	16	40	20	20	20	28,36 €
MCL10-12-40/B	M10	M12	16	40	20	20	20	28,36 €
MCL10-16-40/B	M10	M16	22	40	20	20	20	40,53 €
MCL12-16-40/B	M12	M16	22	40	20	20	20	40,53 €
Stainless steel								
MCL6-8-40/SS/B	M6	M8	13	40	20	20	20	53,60 €
MCL6-10-40/SS/B	M6	M10	16	40	20	20	20	70,75 €
MCL8-10-40/SS/B	M8	M10	16	40	20	20	20	70,75 €
MCL8-12-40/SS/B	M8	M12	16	40	20	20	20	70,75 €
MCL10-12-40/SS/B	M10	M12	16	40	20	20	20	70,75 €
MCL10-16-40/SS/B	M10	M16	22	40	20	20	20	130,85 €
MCL12-16-40/SS/B	M12	M16	22	40	20	20	20	130,85 €

Dimensions in mm

 Our other products




FTSN

Supported shaft for linear guide, Steel shaft / Aluminium support



CF

 Cam follower, Standard - steel



RTN

BoWex® curved tooth gear coupling, Nylon



CHA_GC_14SS

Stainless steel garnet hinge, To screw



PPG

Indexing plunger with flange, With horizontal mounting flange




YG1

HEAVY DUTY spur gear, Steel 35NCD6



TAC

Rigging screw (hook/eye), Steel

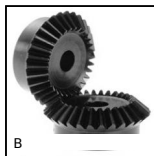

B

Steel bevel gear, 1:1




PTAF80-PAMF80

Articulated fixable foot with pressed flange



M2

 Worm and wheel set, Hardened steel



BETA

Hitch pin, Hitch



ZDB

Machined plastic bevel gear, 2:1

Complementary products



 
MHXred

Reducing sleeve male/female, Hexagonal - steel



MCLred

Reducing sleeve female/female, Cylindrical - stainless steel



TIFbout

Threaded stud - DIN976A, Steel



MCL

Cylindrical threaded sleeve, Cylindrical - steel