

Plastic bevel gear



Ratio

2:1 3:1


- Module 1.5 to 3
- Moulded parts
- Material:
Nylon 6 reinforced with 30% glass fibre

Options

- We are unable to modify these parts


Info.

- The 2 bevels should form a matching pair
- Moulded pre-bore must be machined to suit the application
- **Pilot bore dimension given as a guide only

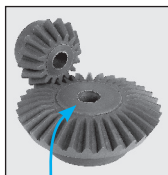


*ØA: Pilot bore requires finishing***

Moulded nylon PA6

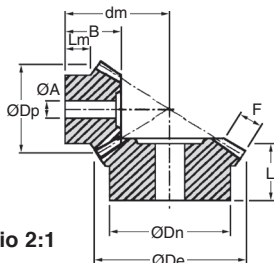

Ratio 2:1

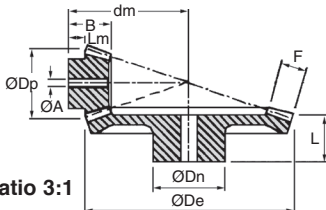

Ratio 3:1

Economy range

DISCOUNTS

Qty	1+	10+	20+	50+	100+
Disc.	List	-10%	-15%	-25%	On request

Part number	Teeth		Pilot bore no guaranteed					ØA*	dm	L	Lm	Stock*	Price each 1 to 9
	Z	Module	ØDe	ØDp	B	F	ØDn						
Ratio 2:1													
MDB1.5-16	16	1,5	26,7	24	18,5	8	18	8	34,9	17,0	10,3	✓	7,07 €
MDB1.5-32	32	1,5	49,3	48	20,0	8	32	12	27,5	17,5	10,0	✓	12,12 €
MDB2-16	16	2,0	35,6	32	23,0	10	24	10	45,4	21,0	12,2	✓	8,25 €
MDB2-32	32	2,0	65,8	64	25,0	10	40	12	35,2	22,0	10,0	✓	18,08 €
MDB2.5-16	16	2,5	44,4	40	27,5	12	30	12	56,0	25,0	14,4	✓	10,65 €
MDB2.5-32	32	2,5	82,2	80	30,0	12	50	15	43,5	26,5	10,0	✓	22,40 €
MDB3-16	16	3,0	53,4	48	28,0	15	40	14	61,6	25,0	11,6	✓	18,65 €
MDB3-32	32	3,0	98,7	96	33,0	15	60	15	50,4	30,5	15,0	✓	37,85 €
Ratio 3:1													
MTB1.5-16	16	1,5	26,9	24	22,0	12	20	8	46,3	21,0	9,7	✓	8,41 €
MTB1.5-48	48	1,5	72,9	72	21,0	12	42	15	29,2	19,0	12,0	✓	16,16 €
MTB2.5-16	16	2,5	44,7	40	28,0	18	34	14	70,4	26,0	9,2	-	13,53 €
MTB2.5-48	48	2,5	121,6	120	32,0	18	60	20	44,6	27,0	16,0	-	25,98 €
MTB3-16	16	3,0	53,7	48	30,0	18	35	10	84,2	28,0	11,2	-	19,04 €
MTB3-48	48	3,0	145,9	144	38,0	18	50	20	54,1	32,0	19,0	-	38,81 €

*Depending on availability - Dimensions in mm

Our other products



RBGpl

Swivel castor with plate, Steel - grey rubber



P70

Worm and wheel gear reducer, up to 164 Nm



KB_UU

Closed linear precision bearing, Precision - steel



GG2

Ground spur gear, Heat treated steel



DCA

Suction cup, 1.5 bellows, silicon



SCA

Flat cable clamp, Steel



RAG-12-M8

Roller guide accessory, Anchoring system



DOG258

Motor-gearbox 12V and 24V DC, from 12 to 15 Nm



BAG-MI

Split shaft collar with clamp lever, Steel



BCAss

Stainless steel splined bush, Inox



PF30NM

Worm and wheel gear reducer, up to 8.8 Nm



CNA-CNG

Right angled mounting plate, Right angled mounting plate for ball jo...

Complementary products



SSDB

Stainless steel bevel gear, 2:1



DB

Steel bevel gear, 2:1