

Nylon PA6 moulded

Ratio 2:1 3:1


- **Module 1.5 to 3**
- Moulded parts
- **Material:**
Nylon 6 reinforced with 30% glass fibre

Options


- **HPC are unable to modify these parts**
- Please refer to the **ZDB..** or **ZTB..** ranges for parts that can be modified

Info.


- Two identical gears must be ordered to make a pair

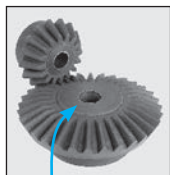

ϕA : Pre-bored hole must be finished

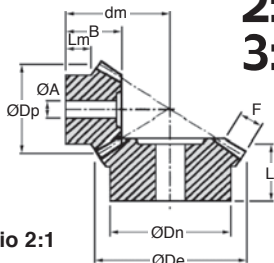

Ratio 2:1

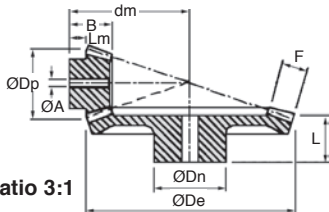

Ratio 3:1

Economy range

DISCOUNTS

Qty	1+	10+	20+	50+	100+
Disc.	List	-10%	-15%	-25%	On request

Part number	Teeth											Price each 1 to 9
	Z	Module	ØDe	ØDp	B	F	ØDn	ØA	dm	L	Lm	
Ratio 2:1												
MDB1.5-16	16	1,5	26,7	24	18,5	8	18	8	34,9	17,0	10,3	7,07 €
MDB1.5-32	32	1,5	49,3	48	20,0	8	32	12	27,5	17,5	10,0	13,12 €
MDB2-16	16	2,0	35,6	32	23,0	10	24	10	45,4	21,0	12,2	8,72 €
MDB2-32	32	2,0	65,8	64	25,0	10	40	12	35,2	22,0	10,0	19,46 €
MDB2.5-16	16	2,5	44,4	40	27,5	12	30	12	56,0	25,0	14,4	10,91 €
MDB2.5-32	32	2,5	82,2	80	30,0	12	50	15	43,5	26,5	10,0	24,91 €
MDB3-16	16	3,0	53,4	48	28,0	15	40	14	61,6	25,0	11,6	19,74 €
MDB3-32	32	3,0	98,7	96	33,0	15	60	15	50,4	30,5	15,0	41,30 €
Ratio 3:1												
MTB1.5-16	16	1,5	26,9	24	22,0	12	20	8	46,3	21,0	9,7	8,72 €
MTB1.5-48	48	1,5	72,9	72	21,0	12	42	15	29,2	19,0	12,0	18,70 €
MTB2.5-16	16	2,5	44,7	40	28,0	18	34	14	70,4	26,0	9,2	14,31 €
MTB2.5-48	48	2,5	121,6	120	32,0	18	60	20	44,6	27,0	16,0	28,13 €
MTB3-16	16	3,0	53,7	48	30,0	18	35	10	84,2	28,0	11,2	22,29 €
MTB3-48	48	3,0	145,9	144	38,0	18	50	20	54,1	32,0	19,0	41,30 €

Dimensions in mm

Our other products



LVT

Miniature motorised actuator, 2 ampers



ZBconique

Machined plastic bevel gear (delrin), 1:1



SRG

Adjustable latch clamp with catch-plate, Stroke from 117,4mm to 128mm



CHAM5270SS

Hinge (stainless steel), Marine



BAC105

Storage bin, 8mm



SH0

Parallel axis helical gear, Steel 20NCD2



HLC19

Right angle bevel gearbox, Up to 43Nm



TCLar

Automatic tightener for chains, With wide guide



DOMI30

DOMILINE - Accessories, Turntable




BOX-CSss

Hose clamp, Box set of stainless steel hose clamps



BLHB40

Right angled gearbox, up to 10.3 Nm

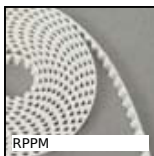

RPPM

RPP type belt by the metre, RPP5 Steel cored polyurethane

Complementary products



TB

Bevel gear - Steel 60C40, 3:1



TB_ECO

Bevel gear - Steel C43, 3:1



TB_ECO

Bevel gear - Steel C43, 3:1