



Stainless steel shackle with eye bolt

Pin diameters 5-20mm


MDRss

- Lifting shackle
- Material: Stainless steel 316
- No marking on the product

Info.

- SWL: SAFE WORKING LOAD.
The Safe Working Load is calculated by dividing the Breaking Strength by a factor of safety of 5.

stainless steel

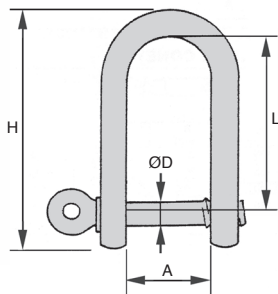

DISCOUNTS

Qty	1+	5+	10+	20+	30+
Disc.	List	-5%	-10%	-15%	On request

Part number	Pin ØD	A	L	H	SWL (kg)	Weight (kg)	Stock*	Price each 1 to 4
MDR1-05/SS	5	9,5	23,0	33	190	0,015	✓	3,58 €
MDR1-06/SS	6	12,0	24,0	37	360	0,030	✓	3,74 €
MDR1-08/SS	8	16,0	35,0	50	540	0,060	✓	4,46 €
MDR1-10/SS	10	19,3	45,6	65	720	0,125	✓	6,41 €
MDR1-12/SS	12	27,0	48,0	72	1080	0,200	✓	11,47 €
MDR1-14/SS	14	28,0	57,0	83	1260	0,310	✓	17,03 €
MDR1-16/SS	16	32,8	59,0	89	1680	0,510	✓	27,30 €
MDR1-20/SS	19	38,0	88,0	124	2400	0,900	-	53,68 €

*Depending on availability - Dimensions in mm

Our other products



CHA_GC_14SS
Stainless steel garnet hinge, To screw



MSP3815
Masterplate® glueable insert rectangular, rectangular with



WW16
Drylin® W slide, slide assembly



GPLbr
Brush, brass



IBJ
180° ball and socket joints, Steel



T5P_T10P
Connecting plate for T type timing belts, T10



CAP821
Slat top chain acetal, Large range 821



PITAss
Locking bolt, with T handle



UGH25
H Type Guide units, for Ø25 actuators



SDG_SS
Universal adjustable guide support bracket, Stainless



BG
Oldham coupling, With set screw



PARF80
Pressed steel base rigid foot, Swivelling - Ø80

 
Complementary products



MDR
Dee shackle with eye bolt, Steel



MLY_SS
Stainless steel bow shackle with eye bolt, Stainless steel



CAB
Stainless steel cable, Stainless steel



TAC_SS
Stainless steel rigging screw (hook/eye), Stainless steel