



# Stainless steel shackle with eye bolt

Pin diameters 5-20mm


MDRss

- Lifting shackle
- Material: Stainless steel 316
- No marking on the product

## Info.

- SWL: SAFE WORKING LOAD.  
The Safe Working Load is calculated by dividing the Breaking Strength by a factor of safety of 5.

stainless steel

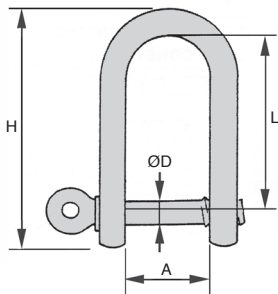

## DISCOUNTS

Qty	1+	5+	10+	20+	30+
Disc.	List	-5%	-10%	-15%	On request

Part number	Pin ØD	A	L	H	SWL (kg)	Weight (kg)	Stock*	Price each 1 to 4
MDR1-05/SS	5	9,5	23,0	33	190	0,015	✓	3,58 €
MDR1-06/SS	6	12,0	24,0	37	360	0,030	✓	3,74 €
MDR1-08/SS	8	16,0	35,0	50	540	0,060	✓	4,46 €
MDR1-10/SS	10	19,3	45,6	65	720	0,125	✓	6,41 €
MDR1-12/SS	12	27,0	48,0	72	1080	0,200	✓	11,47 €
MDR1-14/SS	14	28,0	57,0	83	1260	0,310	✓	17,03 €
MDR1-16/SS	16	32,8	59,0	89	1680	0,510	✓	27,30 €
MDR1-20/SS	19	38,0	88,0	124	2400	0,900	-	53,68 €

\*Depending on availability - Dimensions in mm

## Our other products



BOX-TOR-A

Box set of Nitrile O-rings in nitrile, 2.90 x 1.78mm to 28.17 x 3.53




PSG2

Spur gear - precision range, Pre-hardened Steel 35NCD6



CHAR

Spring hinge, screwed

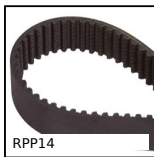

RPP14

RPP heavy duty timing belt, RPP14



FTSN

Supported shaft for linear guide, Steel shaft / Aluminium support



WJUM20

Drylin® W bearing block, Slide




MSP19

Masterplate® glueable insert Ø19/Ø20, Cylindrical with nut




RPB

 Ball screw bearing unit, Support



VAB

 Ballscrew, supplied by the metre, Rolled ballscrew, per metre



RPP8

RPP heavy duty timing belt, RPP8



PR125rehausse

Extension for articulated foot Ø123, articulated foot PR125



SBF

Sealed flange bearing unit for Food Industry, cover

## Complementary products



 
MDR

Dee shackle with eye bolt, Steel



MLY\_SS

Stainless steel bow shackle with eye bolt, Stainless steel



CAB

Stainless steel cable, Stainless steel



TAC\_SS

Stainless steel rigging screw (hook/eye), Stainless steel