



# Stainless steel shackle with eye bolt

Pin diameters 5-20mm


MDRss

- Lifting shackle
- Material: Stainless steel 316
- No marking on the product

## Info.

- SWL: SAFE WORKING LOAD.  
The Safe Working Load is calculated by dividing the Breaking Strength by a factor of safety of 5.

stainless steel

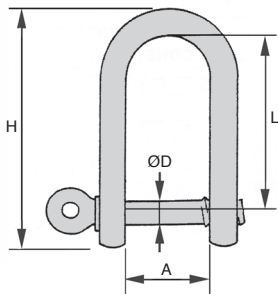

## DISCOUNTS

Qty	1+	5+	10+	20+	30+
Disc.	List	-5%	-10%	-15%	On request

Part number	Pin ØD	A	L	H	SWL (kg)	Weight (kg)	Stock*	Price each 1 to 4
MDR1-05/SS	5	9,5	23,0	33	190	0,015	✓	3,58 €
MDR1-06/SS	6	12,0	24,0	37	360	0,030	✓	3,74 €
MDR1-08/SS	8	16,0	35,0	50	540	0,060	✓	4,46 €
MDR1-10/SS	10	19,3	45,6	65	720	0,125	✓	6,41 €
MDR1-12/SS	12	27,0	48,0	72	1080	0,200	✓	11,47 €
MDR1-14/SS	14	28,0	57,0	83	1260	0,310	✓	17,03 €
MDR1-16/SS	16	32,8	59,0	89	1680	0,510	✓	27,30 €
MDR1-20/SS	19	38,0	88,0	124	2400	0,900	-	53,68 €

\*Depending on availability - Dimensions in mm

## Our other products



CHTRB

Single and dual output gearboxes, Up to 4,7 Nm



Q7

Angular contact ball bearing, Steel



GAL48\_OMNI

Omni-directional roller, Omni-directional



EMR

Fast-locking knurled nut, Knurled



BLHB20

Right angled gearbox, bored shafts, up to 1.77 Nm



PRF\_BP

Doorstop for aluminium profile, Swing door stop



ES

Simple support base (bipod), Plastic



IN0

Internal gear, Steel 20NCD2



M1

Worm and wheel set, Non hardened steel




PRF3232

Standard aluminium profile, 32 x 32 mm



PSG1255

Spur gear - precision range, Stainless steel

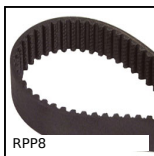

RPP8

RPP heavy duty timing belt, RPP8

## Complementary products



 
MDR

Dee shackle with eye bolt, Steel



MLY\_SS

Stainless steel bow shackle with eye bolt, Stainless steel



CAB

Stainless steel cable, Stainless steel



TAC\_SS

Stainless steel rigging screw (hook/eye), Stainless steel