



Stainless steel shackle with eye bolt

Pin diameters 5-20mm


MDRss

- Lifting shackle
- Material: Stainless steel 316
- No marking on the product

Info.

- SWL: SAFE WORKING LOAD.
The Safe Working Load is calculated by dividing the Breaking Strength by a factor of safety of 5.

stainless steel

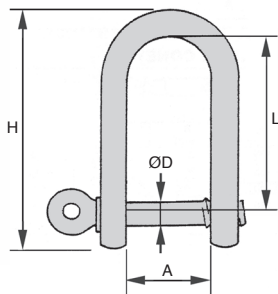

DISCOUNTS

Qty	1+	5+	10+	20+	30+
Disc.	List	-5%	-10%	-15%	On request

Part number	Pin ØD	A	L	H	SWL (kg)	Weight (kg)	Stock*	Price each 1 to 4
MDR1-05/SS	5	9,5	23,0	33	190	0,015	✓	3,58 €
MDR1-06/SS	6	12,0	24,0	37	360	0,030	✓	3,74 €
MDR1-08/SS	8	16,0	35,0	50	540	0,060	✓	4,46 €
MDR1-10/SS	10	19,3	45,6	65	720	0,125	✓	6,41 €
MDR1-12/SS	12	27,0	48,0	72	1080	0,200	✓	11,47 €
MDR1-14/SS	14	28,0	57,0	83	1260	0,310	✓	17,03 €
MDR1-16/SS	16	32,8	59,0	89	1680	0,510	✓	27,30 €
MDR1-20/SS	19	38,0	88,0	124	2400	0,900	-	53,68 €

*Depending on availability - Dimensions in mm

Our other products



RBGtc

Swivel castor with central hole, Steel - grey rubber



NKIB

Combined bearing with inner ring, Axial load in both directions



RAS

90° ball and socket joints DIN71802, Stainless steel



DOMI_MD

Domino rotary table, 40/1




UGH40

H Type Guide units, For Ø40 actuators



BPM_LOK

 Long-Lok slotted spring plunger with ball tip, LONG-LOK - Steel



VKM

Square steel nut, Steel - 1 thread



TBD

Manual leadscrew table with opposing threads, 12mm guide rods



GRP2-14-A

Spring pin ISO8740, splined ISO 8740



CHAE6555

Decorative screwed hinge, Aluminium



ATZY

Diabolo shaped elastomount, Steel



JCSss

Single stainless steel universal joint, Low duty

Complementary products




MDR

Dee shackle with eye bolt, Steel



MLY_SS

Stainless steel bow shackle with eye bolt, Stainless steel

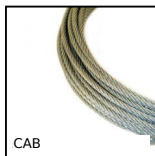

CAB

Stainless steel cable, Stainless steel



TAC_SS

Stainless steel rigging screw (hook/eye), Stainless steel