


# Cylindrical revolving handle



MEP

Technopolymer with steel  
or **stainless steel** shaft

- Cylindrical revolving handle with hexagonal blocking insert
- Operating element
- Material :
  - Body: Black glass fibre reinforced polyamide
  - Threaded shaft: Plated steel or stainless steel

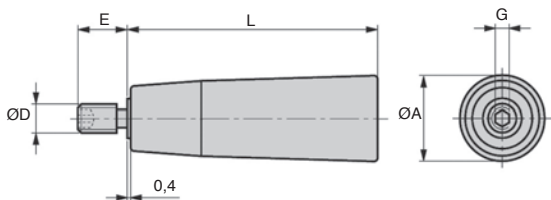


## DISCOUNTS

Qty	1+	6+	10+	20+
Disc. List	-5%	-10%	On request	

Part number	Steel	Stainless steel	ØA	L	ØD	E	G	Stock*		Price each 1 to 5	
								Steel	Stainless steel	Steel	Stainless steel
MEP21-50	MEP21-50/SS	21	50	M6	13	3	✓	✓	6,03 €	17,82 €	
MEP23-70	MEP23-70/SS	23	70	M8	14	4	✓	✓	7,46 €	21,21 €	
MEP26-90	MEP26-90/SS	26	90	M10	17	5	✓	✓	8,47 €	24,09 €	

\*Depending on availability - Dimensions in mm
 
## Our other products



T type timing belt,  
T2.5 Steel cored  
polyurethane



Idler sprocket for slat  
top chain, Range 882



Open precision linear  
bearing, Precision -  
steel



Stainless steel Dee  
shackle with eye bolt,  
Stainless steel



Anti-vibration  
machine mount, Oval  
base plate



Cylindrical sintered  
bronze bush, Self-  
lubricating sintered  
bronze



Machined plastic  
bevel gear , 1:1



Steel bevel gear, 2:1



Manual lock, Manual  
latch



Lock for aluminium  
profile, Lock



Right angled support  
clamp, Right angled  
support clamp



Connecting plate for  
RPP type timing belts,  
RPP8

## Complementary products



Revolving handle for  
handwheel, Fixed



Arm with rotating  
handle, Prebored



Arm with rotating  
handle, Square bore



3-spoked handwheel  
with handle,  
Polyamide