

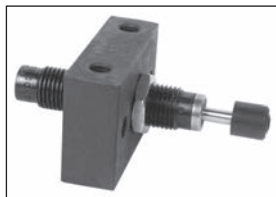



- Universal flange for shock-absorber

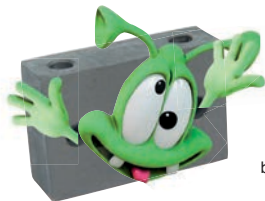

Typical application

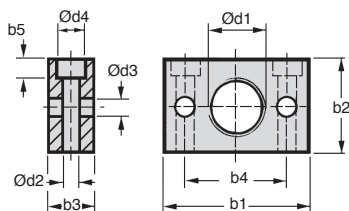

MF10 to 14

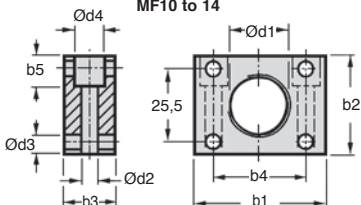

MF20 to 25

DISCOUNTS

Qty	1+	6+	10+	15+
Disc.	List	-10%	-15%	On request

Part number	Ød1	Ød2	Ød3	Ød4	b1	b2	b3	b4	b5	For shock-absorber		Price each
										Stock*	1 to 5	
MF-10	M10x1	4,5	4,5	8	38	25	12	25	5	MC25	✓	43,91 €
MF-12	M12x1	4,5	4,5	8	38	25	12	25	5	MC75	✓	43,91 €
MF-14	M14x1,5	4,5	4,5	8	45	29	16	35	5	MC150	-	47,23 €
MF-20	M20x1,5	5,5	5,5	10	47	35	16	35	10	RMSA500	-	58,71 €
MF-25	M25x1,5	5,5	5,5	10	47	35	16	35	10	RMSA600-900	-	58,69 €

*Depending on availability - Dimensions in mm

Our other products



Female wing knob,
With blind thread



Chain sprocket - steel,
15.875 (DIN 10B-1)



Castor for aluminium
profile, No brake



Cam follower without
axial guide, With
interior ring



Worm and wheel set,
Hardened steel



Bells coupling
Gerwah®, from 0.5 to
12Nm



Sealing washer
Hygienic Usit®,
Stainless steel - Black
EPDM



Hexagonal headed
screw Hygienic
Design®, Stainless
steel



Locking pin, with ring



Linear ball slide -
Stainless steel balls,



Worm and wheel set,
Unhardened steel



Standard aluminium
profile, 45 x 45 mm

Complementary products



Self-compensating
shock-absorber, Self-
compensating -
without adjust...



Adjustable shock-
absorber, Adjustable