

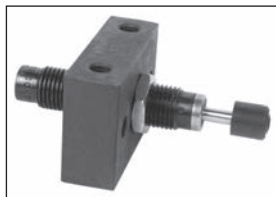



- Universal flange for shock-absorber

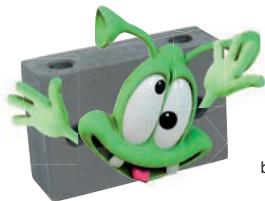

Typical application

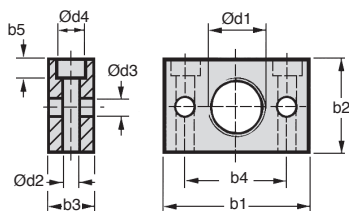

MF10 to 14

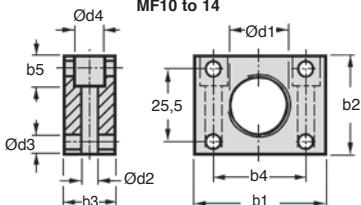

MF20 to 25

DISCOUNTS

Qty	1+	6+	10+	15+
Disc.	List	-10%	-15%	On request


Part number	Ød1	Ød2	Ød3	Ød4	b1	b2	b3	b4	b5	For shock-absorber		Price each
										Stock*	1 to 5	
MF-10	M10x1	4,5	4,5	8	38	25	12	25	5	MC25	✓	43,91 €
MF-12	M12x1	4,5	4,5	8	38	25	12	25	5	MC75	✓	43,91 €
MF-14	M14x1,5	4,5	4,5	8	45	29	16	35	5	MC150	-	47,23 €
MF-20	M20x1,5	5,5	5,5	10	47	35	16	35	10	RMSA500	-	58,71 €
MF-25	M25x1,5	5,5	5,5	10	47	35	16	35	10	RMSA600-900	-	58,69 €

*Depending on availability - Dimensions in mm

Our other products



AC
Strike for toggle latch,
13mm

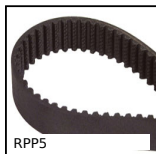

RPP5
RPP heavy duty
timing belt, RPP5



EIM
Stainless steel U bolt,
Stainless steel




RPCplss
Swivel castor with
plate, Stainless steel -
Polyamide



S2B
Short linear bearing
housing, Closed - Slim



MAX26
Motor-gearbox 12V
and 24V DC, from
0,075 to 0,6Nm

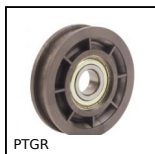

PTGR
Tensioner pulley, For
round belts



PRF3232
Standard aluminium
profile, 32 x 32 mm



SUPCC
Self-centering
clamping hub steel,
With lock nut



DOMI30
Accessories, Fixing kit



UCP_PBT
Stainless/Polymer
pillow block bearing,
Polymer and stainless



T2
T type timing belt,
T2.5 Steel cored
polyurethane

Complementary products



MC
Self-compensating
shock-absorber, Self-
compensating -
without adjust...



RMSA
Adjustable shock-
absorber, Adjustable