



- Universal flange for shock-absorber



Typical application

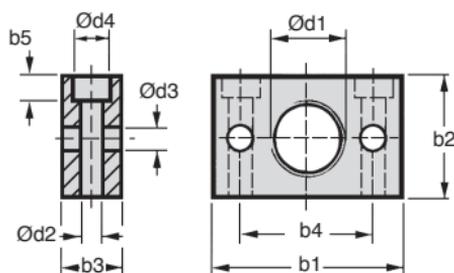

MF10 to 14

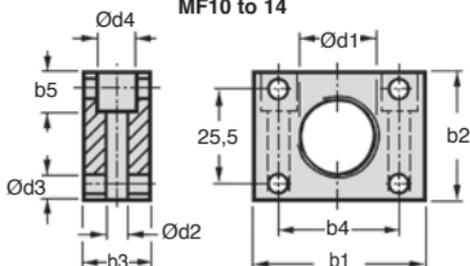

MF20 to 25

### DISCOUNTS

Qty	1+	6+	10+	15+
Disc.	List	-10%	-15%	On request

Part number	Ød1	Ød2	Ød3	Ød4	b1	b2	b3	b4	b5	For shock-absorber		Price each
										Stock*	1 to 5	
MF-10	M10x1	4,5	4,5	8	38	25	12	25	5	MC25	✓	43,91 €
MF-12	M12x1	4,5	4,5	8	38	25	12	25	5	MC75	✓	43,91 €
MF-14	M14x1,5	4,5	4,5	8	45	29	16	35	5	MC150	-	47,23 €
MF-20	M20x1,5	5,5	5,5	10	47	35	16	35	10	RMSA500	-	58,71 €
MF-25	M25x1,5	5,5	5,5	10	47	35	16	35	10	RMSA600-900	-	58,69 €

\*Depending on availability - Dimensions in mm

## Our other products



DOG111

Motor-gearbox 12V and 24V DC, from 1.5 to 6 Nm



LRR

Spring loaded latch, Spring loaded latch



DILC

Indexing plunger with cam, with cam




NKXR

Combined bearing without inner ring, Needle and cylindrical rollers




T5P\_T10P

Connecting plate for T type timing belts, T10

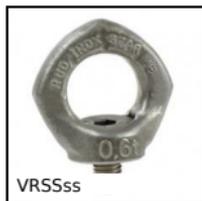

VRSSss

Male swivelling lifting rings stainless steel, Male swivelling - s...

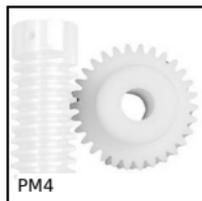

PM4

Wormwheel, Machined plastic (delrin)



VQTplqn

Quarter-turn clamp lock - Clamping plate, Flush mounting




GBMf

Flanged leadscrew nut, Flanged nut - Multiple starts



SDC

Positioning sleeve for indexing pin, For pin Ø4 to Ø12

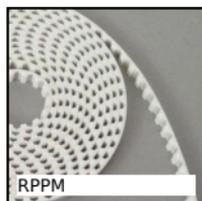

RPPM

RPP type belt per metre, RPP14 Steel cored polyurethane



PSG125S

Spur gear - precision range, Stainless steel 316

## Complementary products



MC

Self-compensating shock-absorber, Self-compensating - without adjust...



RMSA

Adjustable shock-absorber, Adjustable