

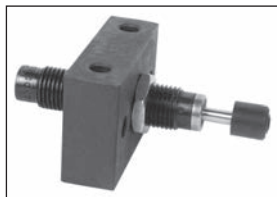



- Universal flange for shock-absorber

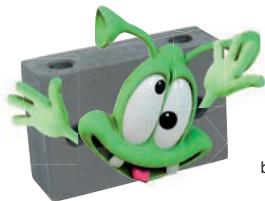

Typical application

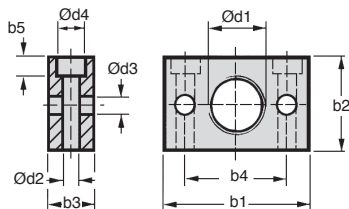

MF10 to 14

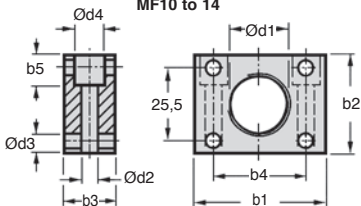

MF20 to 25

### DISCOUNTS

Qty	1+	6+	10+	15+
Disc.	List	-10%	-15%	On request

Part number	Ød1	Ød2	Ød3	Ød4	b1	b2	b3	b4	b5	For shock-absorber		Price each
										Stock*	1 to 5	
MF-10	M10x1	4,5	4,5	8	38	25	12	25	5	MC25	✓	43,91 €
MF-12	M12x1	4,5	4,5	8	38	25	12	25	5	MC75	✓	43,91 €
MF-14	M14x1,5	4,5	4,5	8	45	29	16	35	5	MC150	-	47,23 €
MF-20	M20x1,5	5,5	5,5	10	47	35	16	35	10	RMSA500	-	58,71 €
MF-25	M25x1,5	5,5	5,5	10	47	35	16	35	10	RMSA600-900	-	58,69 €

 
\*Depending on availability - Dimensions in mm

## Our other products



PW\_PWG25

Wheel - precision range, Bronze



LAT2

2A motorised linear actuator, 2 amperes




RURp

Fixed castor with plate, Polyurethane - Aluminium rim (Free running)



PM2

 Worm and wheel set, Bronze




VAB

Ballscrew, supplied by the metre, Rolled ballscrew, per metre



CHM90

 Worm and wheel gear reducer, up to 540 Nm



RDE-W

Sealing washer Hygienic Usit®, Stainless steel - White EPDM



SSE

Stainless steel spherical bearing, Stainless steel / PTFE



ACLLPP

Latch for aluminium profile, Spring



PAMF80EB

Articulated foot with sheet metal base



ZHG5

Plastic spur gear, Machined plastic



SCE

U-shaped cable clamp, Steel

## Complementary products



MC

Self-compensating shock-absorber, Self-compensating - without adjust...



RMSA

Adjustable shock-absorber, Adjustable