

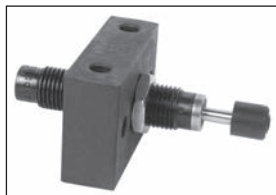



- Universal flange for shock-absorber

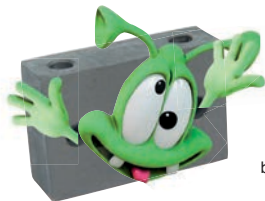

Typical application

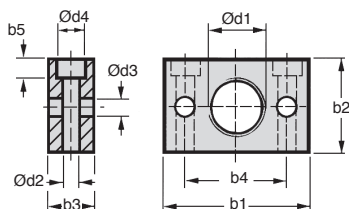

MF10 to 14

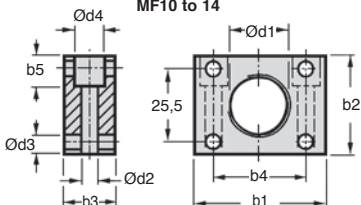

MF20 to 25

DISCOUNTS

Qty	1+	6+	10+	15+
Disc.	List	-10%	-15%	On request

Part number	Ød1	Ød2	Ød3	Ød4	b1	b2	b3	b4	b5	For shock-absorber		Price each
										Stock*	1 to 5	
MF-10	M10x1	4,5	4,5	8	38	25	12	25	5	MC25	✓	43,91 €
MF-12	M12x1	4,5	4,5	8	38	25	12	25	5	MC75	✓	43,91 €
MF-14	M14x1,5	4,5	4,5	8	45	29	16	35	5	MC150	-	47,23 €
MF-20	M20x1,5	5,5	5,5	10	47	35	16	35	10	RMSA500	-	58,71 €
MF-25	M25x1,5	5,5	5,5	10	47	35	16	35	10	RMSA600-900	-	58,69 €

*Depending on availability - Dimensions in mm

Our other products



DPAR_DKON

Conical elasto buffer,
Steel



LQT

Mechanical catch,
Quick closing catch



MEB

Moulded plastic bevel
gear (nylon), 1:1



CLM

Male clevis end, Steel
short



BLH30

Right angled gearbox,
from 1.32 to 4.40 Nm




PW_PWG05

Worm - precision
range, Steel



GALRUB

60mm rubber wheel
for conveyor belt,
Rubber

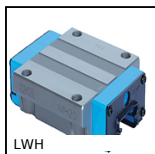

LWH

High rigidity linear
slide, Chariot - from
9320 N to 71300 N



HTD8M_20

HTD Heavy duty
timing pulley, HTD8
Cast



PRF_T

Corner reinforcement,
Corner reinforcement



GLB

Small 6 lobe threaded
handle - female,
Technopolymer -
Stainless steel



SLBE

Indexing plunger -
Spacer, Spacer for
9320 N and 71300 N
index bolts

Complementary products



MC

Self-compensating
shock-absorber, Self-
compensating -
without adjust...



RMSA

Adjustable shock-
absorber, Adjustable