

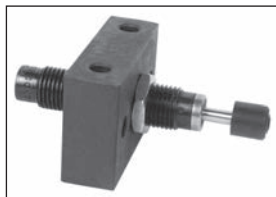



- Universal flange for shock-absorber

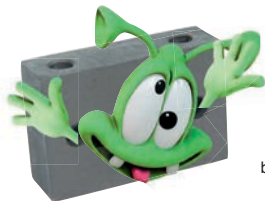

Typical application

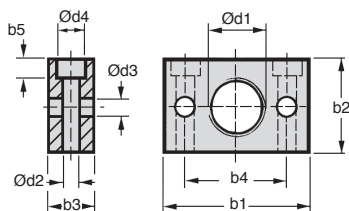

MF10 to 14

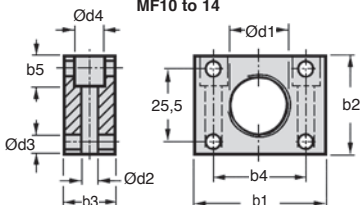

MF20 to 25

DISCOUNTS

Qty	1+	6+	10+	15+
Disc.	List	-10%	-15%	On request

Part number	Ød1	Ød2	Ød3	Ød4	b1	b2	b3	b4	b5	For shock-absorber		Price each
										Stock*	1 to 5	
MF-10	M10x1	4,5	4,5	8	38	25	12	25	5	MC25	✓	43,91 €
MF-12	M12x1	4,5	4,5	8	38	25	12	25	5	MC75	✓	43,91 €
MF-14	M14x1,5	4,5	4,5	8	45	29	16	35	5	MC150	-	47,23 €
MF-20	M20x1,5	5,5	5,5	10	47	35	16	35	10	RMSA500	-	58,71 €
MF-25	M25x1,5	5,5	5,5	10	47	35	16	35	10	RMSA600-900	-	58,69 €

*Depending on availability - Dimensions in mm

Our other products



CHAR7520

Spring hinge, screwed



ZBconique

Machined plastic
bevel gear , 1:1



PM4

Worm and wheel set,
Non hardened steel



CHAE3030PA

Square decorative
screwed hinges,
Polyamide



PRF_ROUL

Castor for aluminium
profile, No brake



AT5-BAR

AT type tooth bar
stock, AT5



CHAR7530

Spring hinge, welded



YG4

HEAVY DUTY spur
gear, Steel 35NCD6



PF30

Worm and wheel gear
reducer, up to 8.80



VPPTss

Stainless steel
handwheel with



ZG4

Plastic spur gear,
Machined plastic



WSS

Symmetrical S shaped
hook, Steel

Complementary products



MC

Self-compensating
shock-absorber, Self-
compensating -
without adjust...



RMSA

Adjustable shock-
absorber, Adjustable