

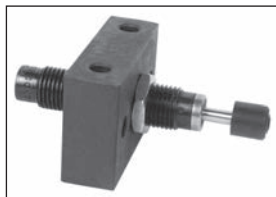



- Universal flange for shock-absorber

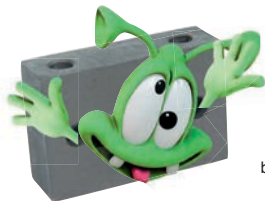

Typical application

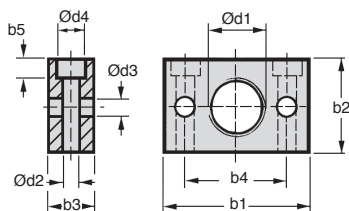

MF10 to 14

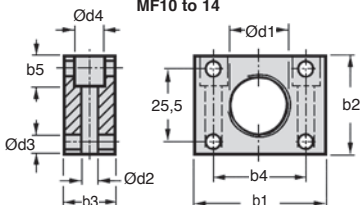

MF20 to 25

DISCOUNTS

Qty	1+	6+	10+	15+
Disc.	List	-10%	-15%	On request

Part number	Ød1	Ød2	Ød3	Ød4	b1	b2	b3	b4	b5	For shock-absorber		Price each
										Stock*	1 to 5	
MF-10	M10x1	4,5	4,5	8	38	25	12	25	5	MC25	✓	43,91 €
MF-12	M12x1	4,5	4,5	8	38	25	12	25	5	MC75	✓	43,91 €
MF-14	M14x1,5	4,5	4,5	8	45	29	16	35	5	MC150	-	47,23 €
MF-20	M20x1,5	5,5	5,5	10	47	35	16	35	10	RMSA500	-	58,71 €
MF-25	M25x1,5	5,5	5,5	10	47	35	16	35	10	RMSA600-900	-	58,69 €

*Depending on availability - Dimensions in mm

Our other products



MHMEP
Arm with rotating handle, Prebored



CHAC4040NP
Square hinge with riveted pin, not drilled, Square with riveted pin,...



PAP
Handle for aluminium profile, Ergonomic handle



VELM4
Screw-on base for hook-and-loop strip, Polyamide



Gal-cardan
Single universal joint eco series, Low duty



G0
Steel spur gear, Steel 20NCD2



TRM
Spur round rack, Steel - module 1-6



LPCM
Lever with cylindrical handle, Black Duroplast, steel lever



PRF_VTM
Hammerhead screw, Hammerhead screw



CHCSS
Socket headed screw, Stainless steel - A2



PTA50
Articulated levelling foot, pressed base



SHW
Plain washer, Steel

Complementary products



MC
Self-compensating shock-absorber, Self-compensating - without adjust...



RMSA
Adjustable shock-absorber, Adjustable