

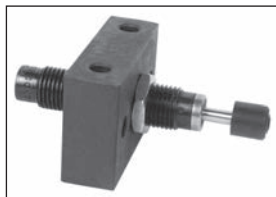



- Universal flange for shock-absorber

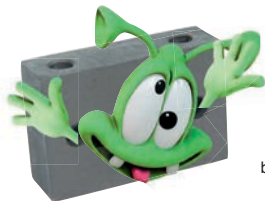

Typical application

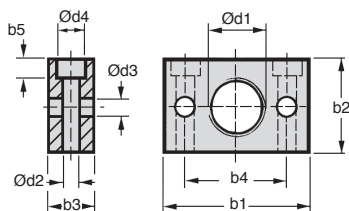

MF10 to 14

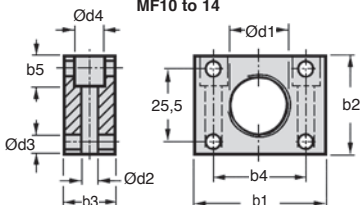

MF20 to 25

DISCOUNTS

Qty	1+	6+	10+	15+
Disc.	List	-10%	-15%	On request

Part number	Ød1	Ød2	Ød3	Ød4	b1	b2	b3	b4	b5	For shock-absorber		Price each
										Stock*	1 to 5	
MF-10	M10x1	4,5	4,5	8	38	25	12	25	5	MC25	✓	43,91 €
MF-12	M12x1	4,5	4,5	8	38	25	12	25	5	MC75	✓	43,91 €
MF-14	M14x1,5	4,5	4,5	8	45	29	16	35	5	MC150	-	47,23 €
MF-20	M20x1,5	5,5	5,5	10	47	35	16	35	10	RMSA500	-	58,71 €
MF-25	M25x1,5	5,5	5,5	10	47	35	16	35	10	RMSA600-900	-	58,69 €

*Depending on availability - Dimensions in mm

Our other products



CLR
Straight clevis,
Straight clevis for use
with a male clevis



BPPL
Mini plain bearing ball
transfer unit, For
countersinking



GE32
Sprung toggle latch
with connecting link,
Standard



CTss
Universal joint,
telescopic, Inox, Light
duty



RJA10_03
Sealing strip, Clipping



DOMI30
Accessories, Turntable



GPB
Threaded spherical
knob, Moulded thread




ASH
Hoist ring for welding,
for straight lifts - for
welding



BAG-MISS
Split shaft collar with
clamp lever, Stainless



BH02
Single housed bearing
assembly, Bearing

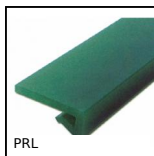

PRL
Wear strip for slat top
chain, L profile to be



CHAR7520
Spring hinge, screwed

Complementary products



MC
Self-compensating
shock-absorber, Self-
compensating -
without adjust...



RMSA
Adjustable shock-
absorber, Adjustable