

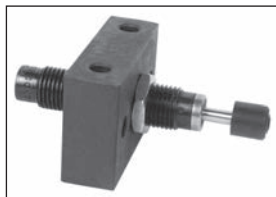



- Universal flange for shock-absorber

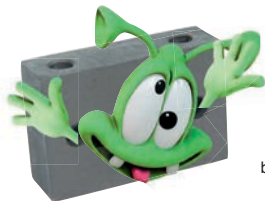

Typical application

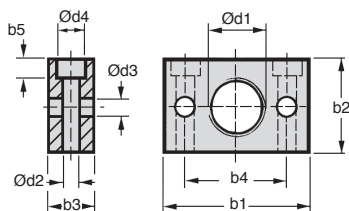

MF10 to 14

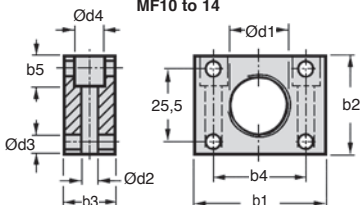

MF20 to 25

DISCOUNTS

Qty	1+	6+	10+	15+
Disc.	List	-10%	-15%	On request


Part number	Ød1	Ød2	Ød3	Ød4	b1	b2	b3	b4	b5	For shock-absorber		Price each
										Stock*	1 to 5	
MF-10	M10x1	4,5	4,5	8	38	25	12	25	5	MC25	✓	43,91 €
MF-12	M12x1	4,5	4,5	8	38	25	12	25	5	MC75	✓	43,91 €
MF-14	M14x1,5	4,5	4,5	8	45	29	16	35	5	MC150	-	47,23 €
MF-20	M20x1,5	5,5	5,5	10	47	35	16	35	10	RMSA500	-	58,71 €
MF-25	M25x1,5	5,5	5,5	10	47	35	16	35	10	RMSA600-900	-	58,69 €

*Depending on availability - Dimensions in mm

Our other products



 Knurled torque knobs
- female, Knurled
threaded torque



Lip seal for panel,
Door seal - Ø 6mm



 
Steel spur gear, Steel
20NCD2




Swivel castor with
central hole, Steel -
grey rubber



Self-locking nut, A2
Stainless steel



 Crossed helical gear
crossed axis at 90°,
Machined plastic
(delrin)



T type timing belt,
T2.5 Steel cored
polyurethane



Brush strip per meter
PP fibres Ø0.2, Black
striated polypropylene



Bracket for aluminium
profile, PRF4590



180° ball and socket
joints, Steel



Symmetrical decorative
screwed hinge,
Polyamide



End cap with threaded
insert for square tube,
With threaded insert

Complementary products



Self-compensating
shock-absorber, Self-
compensating -
without adjust...



Adjustable shock-
absorber, Adjustable