

Spur gear for use in food industry



Ratio

Moulded blue PA6 Nylon

1,5:1-4:1


- Moulded gear for use in food applications
- Pressure angle: 20°
- Material:
Blue glass-fibre reinforced Polyamide
- Two identical gears must be ordered to make a pair

Info

- *Pre-bore after de-moulding, must be machined before installation.
- We are unable to modify these products



Food industry

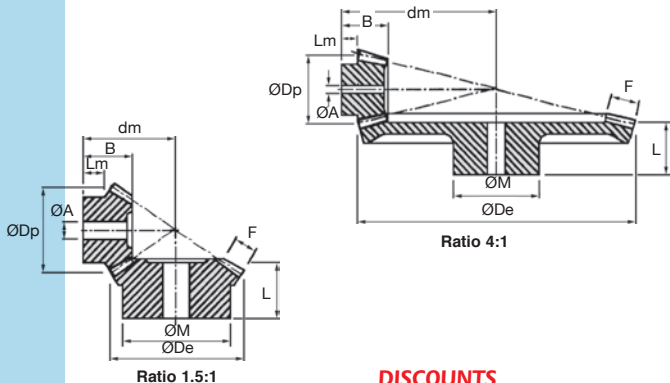

DISCOUNTS

Qty	1+	10+	20+	50+	100+
Disc.	Net	-10%	-15%	-25%	On request

Part N°	Teeth Z	Module	ØDe	ØDp	B	F	ØM Hub	ØA* Pre-bore	dm	L	Lm	Price each. 1 to 9
Ratio 4:1												
MFB2.5-16/ALI	16	2,5	44,9	40	30,5	18	32,5	15	92,6	30,5	11,5	18,85 €
MFB2.5-64/ALI	64	2,5	161,2	160	35,0	18	60,0	20	48,8	28,0	16,5	81,21 €
MFB3-16/ALI	16	3	53,8	48	31,5	20	35,0	10	108	31,5	11	35,19 €
MFB3-64/ALI	64	3	193,5	192	42,0	20	60,0	19	58,8	36,0	22	70,88 €
Ratio 1,5:1												
MHB2-20/ALI	20	2	43,3	40	23,0	10	30,0	8	43,3	23,0	10,2	18,57 €
MHB2-30/ALI	30	2	62,2	60	27,0	10	50,0	11,05	40,6	27,0	15	27,19 €

All dimensions in mm

Our other products



ZHG6

Plastic spur gear,
Machined plastic
(delrin)



BOXbeta

Box of assorted hitch
pins, Boxed set - hitch



MRA_SS

Stainless steel Quick
link, Stainless steel



SCA_SS

Stainless steel flat
cable clamp, Stainless
steel




CHTRB

Single and dual
output gearboxes, Up
to 53,1 Nm



SFWR

End support, Surface
mounting

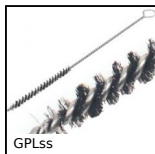


GPLss

Brush, stainless steel



HG5-ECO

 Eco range Spur gear,
Steel C45



CAB

Galvanised steel
cable, Galvanised
steel




M0

Worm and wheel set,
Non hardened steel



TBD

Manual leadscrew
table with opposing
threads, 2kg

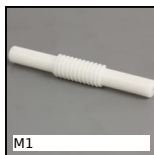

M1

Worm and wheel set,
Machined plastic
(delrin)

Complementary products



MFB_MHB

Moulded plastic bevel
gear (nylon), 4:1