

Crank arm with **rotating handle**


MH_{MEP}

Technopolymer

- Arm with rotating handle
- Operating elements
- Material:
Black glass fibre reinforced polyamide
Matt surface finish

Options

- Alternative bores on request
- Industry standard keyways available

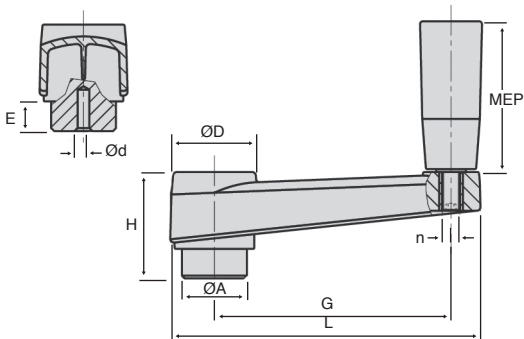

DISCOUNTS

Qty	1+	10+	20+
Disc.	List	-5%	On request

Part number	G	L	ØA	ØD	E	H	Prebored Ød	MEP	n	Stock*	Price each 1 to 9
MH65-MEP	65	87	18	27	10	33	4	21x50	M6	✓	18,08 €
MH80-MEP	80	105	22	30	10	36	4	21x50	M6	✓	20,61 €
MH100-MEP	100	128	24	34	10	40	4	23x70	M8	✓	23,59 €
MH130-MEP	130	162	28	40	14	49	6	26x90	M8	✓	33,28 €
MH160-MEP	160	196	34	45	15	55	6	26x90	M10	✓	42,12 €

*Subject to availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15€/min + prix appel

Our other products



TCXR

Automatic chain tensioner, With steel sprocket



ERT

Sliding nut, For T slot



SHTC

Drylin® Linear table, Maintenance free



SUPccss

Self-centering clamping hub stainless steel, With lock nut



PRF_CH

Cable-carrier chain for aluminium profile, Supplied in metre lengths



TCXR

Automatic chain tensioner, With stainless steel sprocket




SVR5

Screwjack with travelling unit, with moving nut




OPFL_OPPM

 Numerical counter accessories, Operating knob



TIF

 Threaded rod - DIN975, Stainless steel A2



LAT1

1A motorised linear actuator, 1 ampere



PM4

Worm and wheel set, Hardened steel



PRFRTR

Cross connector for aluminium profile, Cross connector

Complementary products



MHQMEP

Arm with rotating handle, Square bore



MHPGR

Arm with folding rotating handle,



MEP

Revolving handle for handwheel, Fixed



PGR

Folding revolving handle for handwheel, Folding