

Crank arm with **rotating handle**


MH_{MEP}

Technopolymer

- Arm with rotating handle
- Operating elements
- Material:
Black glass fibre reinforced polyamide
Matt surface finish

Options

- Alternative bores on request
- Industry standard keyways available

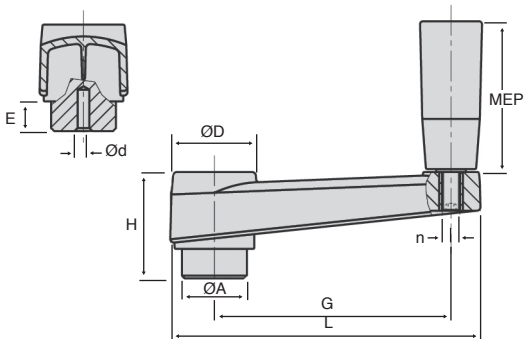

DISCOUNTS

Qty	1+	10+	20+
Disc.	List	-5%	On request

Part number	G	L	ØA	ØD	E	H	Prebored Ød	MEP	n	Stock*	Price each 1 to 9
MH65-MEP	65	87	18	27	10	33	4	21x50	M6	✓	18,08 €
MH80-MEP	80	105	22	30	10	36	4	21x50	M6	✓	20,61 €
MH100-MEP	100	128	24	34	10	40	4	23x70	M8	✓	23,59 €
MH130-MEP	130	162	28	40	14	49	6	26x90	M8	✓	33,28 €
MH160-MEP	160	196	34	45	15	55	6	26x90	M10	✓	42,12 €

*Subject to availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15€/min + prix appel

Our other products



Long-Lok spring plunger with internal hexagonal socket, LONG-LOK - s...



Spur gear - precision range, Case hardened steel 20NCD2



Indexing plunger for sheets, For sheet metal



Screwjack - pivot mounting, Pivoting bracket



Symmetrical S shaped hook stainless steel, Stainless steel



Strike for toggle latch, 25.5mm



Hexagonal headed screw with collar Hygienic Usit®, Stainless steel



Die cast zinc clamping lever - female, Zamak



Manual workbench press, Force up to ...



Oldham coupling, With set screw



Parallel axis helical gear, Steel 20NCD2



Ground spur gear, Heat treated steel

Complementary products



Arm with rotating handle, Square bore



Arm with folding rotating handle,



Revolving handle for handwheel, Fixed



Folding revolving handle for handwheel, Folding