



Crank arm with folding rotating handle



Technopolymer

MHPGR

- Crank arm with folding rotating handle
- Operating elements
- Material:
Black glass fibre reinforced polyamide
Matt surface finish

Options

- Alternative bores on request
- Industry standard keyways available

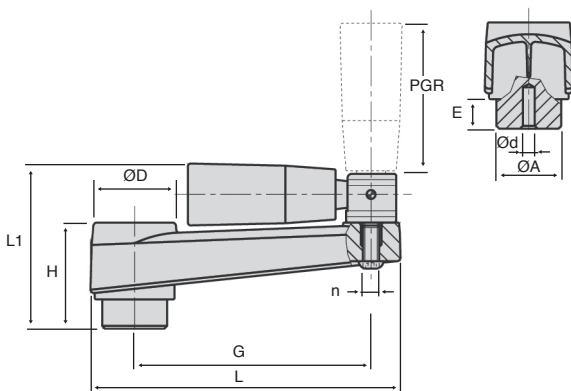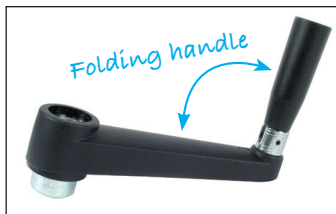


DISCOUNTS

Qty	1+	10+	20+
Disc.	List	-5%	On request

Part number	G	L	L1	ØA	ØD	E	H	Prebored Ød	PGR	n	Stock*	Price each 1 to 9
MH80-PGR	80	105	55	22	30	10	36	4	21x50	M5	-	59,63 €
MH100-PGR	100	128	63	24	34	10	40	4	23x70	M6	✓	60,39 €
MH130-PGR	130	162	74	28	40	14	49	6	23x70	M6	-	70,33 €
MH160-PGR	160	196	86	34	45	15	55	6	26x90	M6	✓	78,39 €

*Subject to availability - Dimensions in mm

 Our other products



PRF_PSP_PR
Dual purpose strip
and cover for
aluminium profile,
Inserts into slot



KB_UU
Closed linear
precision bearing,
Precision - steel




F7-P-AM
Multifunction display,
Magnetic ring



PCM
Fixed cylindrical
handle, Fixed non-
turning handle



BPM-Z
Plastic slotted spring
plunger with ball tip,
Plastic body +
stainle...

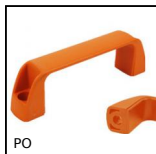

PO
Pull handle - Multi-
sector, Smooth hole



BEK
Bearing housing for
miniature ballscrew,
Bearing housing



DIA
Ring operated locking
bolt, with ring



TCC
Rigging screw
(hook/hook), Steel



SBF
Sealed flange bearing
unit for Food Industry,
cover



BS2
Panamech, Multi-
Beam, Aluminium -
with set screw



VML
Stainless steel
hexagonal headed
thumb screw, Male

Complementary products



MHMEP
Arm with rotating
handle, Prebored



MHQMEP
Arm with rotating
handle, Square bore



V3RA_PTR
3-spoked handwheel
with foldable handle,
Polyamide



SHA_PTR
Handwheel with
folding handle,
Polyamide