



Crank arm with folding rotating handle



Technopolymer

MHPGR

- Crank arm with folding rotating handle
- Operating elements
- Material:
Black glass fibre reinforced polyamide
Matt surface finish

Options

- Alternative bores on request
- Industry standard keyways available

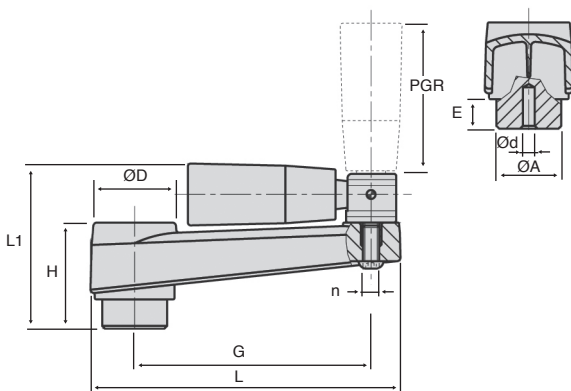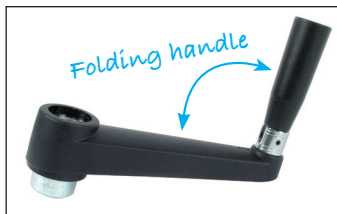

DISCOUNTS

Qty	1+	10+	20+
Disc.	List	-5%	On request

Part number	G	L	L1	ØA	ØD	E	H	Prebored Ød	PGR	n	Stock*	Price each 1 to 9
MH80-PGR	80	105	55	22	30	10	36	4	21x50	M5	-	59,63 €
MH100-PGR	100	128	63	24	34	10	40	4	23x70	M6	✓	60,39 €
MH130-PGR	130	162	74	28	40	14	49	6	23x70	M6	-	70,33 €
MH160-PGR	160	196	86	34	45	15	55	6	26x90	M6	✓	78,39 €

*Subject to availability - Dimensions in mm

Our other products



HLC28
Right angle spiro bevel gearbox, Up to 182Nm



DOMI80
Domino 80 adjustable slide, Slide DOMILINE 80 with counter and handw...



BOXKK
Boxed set of DIN6885A keys, Boxed set - Steel or stainless steel



BAGSS
Stainless steel Clamping collar, Stainless steel



G-ECO
Eco range Spur gear, Steel C45



HSE-HSB
Hexagonal spacer, Brass



PW_PWG15
Wheel - precision range, Bronze



UCP_SS
Stainless steel pillow block bearing, Stainless steel



NKIA
Combined bearing with inner ring, Axial load in one direction



PO
Pull handle - Multi-sector, Tapped recessed insert



PRF_BP
Doorstop for aluminium profile, Swing door stop



BPFL
Sheet steel flanged bearing for light loads, Sheet steel

Complementary products



MHMEP
Arm with rotating handle, Prebored



MHQMEP
Arm with rotating handle, Square bore



V3RA_PTR
3-spoked handwheel with foldable handle, Polyamide



SHA_PTR
Handwheel with folding handle, Polyamide