



Crank arm with rotating handle


Square bore, technopolymer

MHQ_{MEP}

- Crank arm with rotating handle and a square through-bored hole
- Operating elements
- Material:
Black glass fibre reinforced polyamide
Matt surface finish

Options

- Alternative bores on request
- Industry standard keyways available

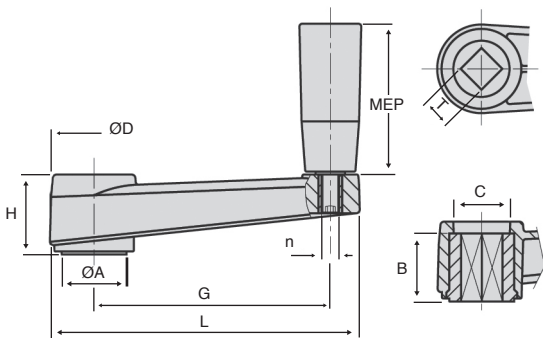


DISCOUNTS

Qty	1+	10+	20+
Disc.	List	-5%	On request

Part number	G	L	ØA	ØD	H	T	B	C	MEP	n	Stock*	Price each
												1 to 9
MHQ65-MEP	65	87	18	27	23	8x8	20	16	21x50	M6	✓	18,89 €
MHQ80-MEP	80	105	22	30	26	10x10	22	19	21x50	M6	✓	21,12 €
MHQ100-MEP	100	128	24	34	30	12x12	27	22	23x70	M8	✓	25,09 €
MHQ130-MEP	130	162	28	40	35	14x14	30	25	26x90	M8	✓	33,64 €
MHQ160-MEP	160	196	34	45	40	17x17	34	28	26x90	M10	✓	43,67 €

*Subject to availability - Dimensions in mm

Our other products

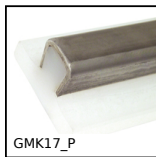

GMK17_P

Flat Guide, Flat guide for conical profile




AZY

Cylindrical elasto mount, Steel



CHNrb

Warning chain with red and white links, Steel

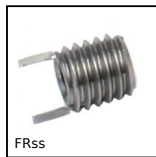

FRss

Stainless steel thread inserts, Stainless steel



MSP19

Masterplate® glueable insert Ø19/Ø20, Cylindrical with nut



DOMI50

Domino 50 adjustable slide, Slide DOMILINE 50 with counter and handw...



HW_HT

Half-rail guide, Wheel



PF30

Worm and wheel gear reducer, up to 8.80 Nm



MSP38

Masterplate® glueable insert Ø38, Self...



MET

Cylindrical sintered bronze bush, Self...



SHA_PTR

Handwheel with folding handle, Fixed



CHAR7530

Spring hinge, welded

Complementary products



MHMEP

Arm with rotating handle, Prebored



MHPGR

Arm with folding rotating handle, Fixed



MEP

Revolving handle for handwheel, Fixed



PGR

Folding revolving handle for handwheel, Folding