


# Hexagonal threaded sleeves

Sta Ste


MHX

Steel or **stainless steel**

- Hexagonal sleeves, through threaded
- Suitable for joining threaded bars
- Materials:
  - Blue galvanised steel S300PB
  - Stainless steel 303
- Sold by the packet

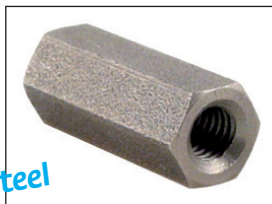

steel or stainless steel

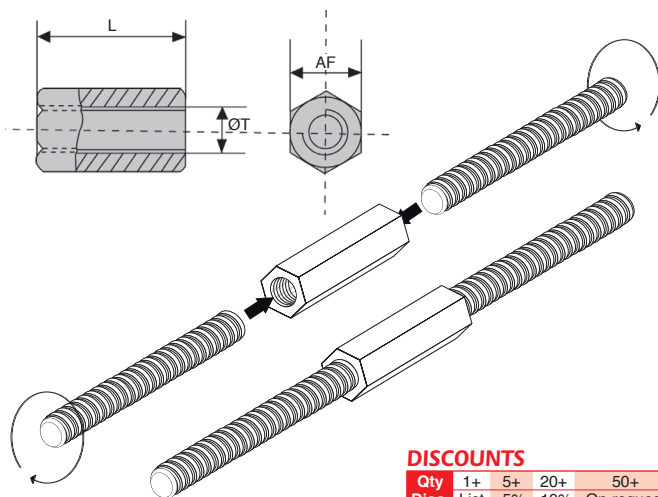

## DISCOUNTS

|       |      |     |      |            |
|-------|------|-----|------|------------|
| Qty   | 1+   | 5+  | 20+  | 50+        |
| Disc. | List | -5% | -10% | On request |

| Part number |                 | Thread<br>ØT | L  | AF  | Qty per<br>packet | Stock* |     | Price per packet<br>1 to 4 |           |
|-------------|-----------------|--------------|----|-----|-------------------|--------|-----|----------------------------|-----------|
| Steel       | Stainless steel |              |    |     |                   | Steel  | Stl | Steel                      | Stl steel |
| MHX3-10/B   | MHX3-10/SS/B    | M3           | 10 | 5,5 | 20                | ✓      | -   | 4,48 €                     | 14,66 €   |
| MHX3-12/B   | MHX3-12/SS/B    | M3           | 12 | 5,5 | 20                | -      | -   | 4,60 €                     | 16,21 €   |
| MHX3-15/B   | MHX3-15/SS/B    | M3           | 15 | 5,5 | 20                | ✓      | -   | 5,07 €                     | 17,85 €   |
| MHX3-18/B   | -               | M3           | 18 | 5,5 | 20                | -      | -   | 5,57 €                     | -         |
| MHX3-20/B   | -               | M3           | 20 | 5,5 | 20                | ✓      | -   | 5,99 €                     | -         |

\*Depending on availability - Dimensions in mm

HPC

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

## DISCOUNTS

|       |      |     |      |            |
|-------|------|-----|------|------------|
| Qty   | 1+   | 5+  | 20+  | 50+        |
| Disc. | List | -5% | -10% | On request |

 
| Part number |                 | Thread |    |      | Qty per packet | Stock* |     | Price per packet 1 to 4 |           |
|-------------|-----------------|--------|----|------|----------------|--------|-----|-------------------------|-----------|
| Steel       | Stainless steel | ØT     | L  | AF   |                | Steel  | Stl | Steel                   | Stl steel |
| MHX4-10/B   | MHX4-10/SS/B    | M4     | 10 | 7,0  | 20             | -      | -   | 4,67 €                  | 16,90 €   |
| MHX4-12/B   | MHX4-12/SS/B    | M4     | 12 | 7,0  | 20             | -      | -   | 4,95 €                  | 18,91 €   |
| MHX4-15/B   | MHX4-15/SS/B    | M4     | 15 | 7,0  | 20             | -      | -   | 5,41 €                  | 21,04 €   |
| MHX4-18/B   | -               | M4     | 18 | 7,0  | 20             | -      | -   | 5,88 €                  | -         |
| MHX4-20/B   | -               | M4     | 20 | 7,0  | 20             | ✓      | -   | 6,60 €                  | -         |
| -           | MHX5-12/SS/B    | M5     | 12 | 8,0  | 20             | -      | ✓   | -                       | 22,32 €   |
| MHX5-15/B   | MHX5-15/SS/B    | M5     | 15 | 8,0  | 20             | ✓      | -   | 6,87 €                  | 23,56 €   |
| -           | MHX5-18/SS/B    | M5     | 18 | 8,0  | 20             | -      | -   | -                       | 24,90 €   |
| MHX5-20/B   | MHX5-20/SS/B    | M5     | 20 | 8,0  | 20             | ✓      | ✓   | 9,52 €                  | 25,33 €   |
| MHX5-25/B   | -               | M5     | 25 | 8,0  | 20             | -      | -   | 10,23 €                 | -         |
| MHX6-15/B   | MHX6-15/SS/B    | M6     | 15 | 10,0 | 20             | ✓      | ✓   | 5,74 €                  | 32,41 €   |
| MHX6-18/B   | MHX6-18/SS/B    | M6     | 18 | 10,0 | 20             | -      | -   | 6,27 €                  | 29,41 €   |
| MHX6-20/B   | MHX6-20/SS/B    | M6     | 20 | 10,0 | 20             | -      | -   | 6,46 €                  | 35,45 €   |
| MHX6-25/B   | MHX6-25/SS/B    | M6     | 25 | 10,0 | 20             | -      | ✓   | 6,78 €                  | 35,96 €   |
| MHX6-30/B   | MHX6-30/SS/B    | M6     | 30 | 10,0 | 20             | ✓      | ✓   | 7,82 €                  | 43,03 €   |
| MHX6-35/B   | -               | M6     | 35 | 10,0 | 20             | ✓      | ✓   | 9,60 €                  | -         |
| MHX6-40/B   | -               | M6     | 40 | 10,0 | 20             | ✓      | ✓   | 10,44 €                 | -         |
| MHX6-50/B   | -               | M6     | 50 | 10,0 | 20             | -      | -   | 17,95 €                 | -         |
| MHX8-15/B   | -               | M8     | 15 | 13,0 | 20             | ✓      | -   | 9,19 €                  | -         |
| MHX8-20/B   | -               | M8     | 20 | 13,0 | 20             | ✓      | -   | 10,63 €                 | -         |
| MHX8-25/B   | MHX8-25/SS/B    | M8     | 25 | 13,0 | 20             | ✓      | ✓   | 13,02 €                 | 60,97 €   |
| MHX8-30/B   | MHX8-30/SS/B    | M8     | 30 | 13,0 | 20             | ✓      | ✓   | 15,02 €                 | 72,22 €   |
| MHX8-35/B   | -               | M8     | 35 | 13,0 | 20             | -      | -   | 17,30 €                 | -         |
| MHX8-40/B   | -               | M8     | 40 | 13,0 | 20             | ✓      | -   | 19,61 €                 | -         |
| MHX8-45/B   | -               | M8     | 45 | 13,0 | 20             | ✓      | -   | 23,36 €                 | -         |
| MHX8-50/B   | -               | M8     | 50 | 13,0 | 20             | ✓      | -   | 29,41 €                 | -         |
| MHX8-60/B   | -               | M8     | 60 | 13,0 | 20             | ✓      | -   | 35,54 €                 | -         |
| MHX10-20/B  | -               | M10    | 20 | 17,0 | 20             | ✓      | -   | 14,82 €                 | -         |
| MHX10-25/B  | MHX10-25/SS/B   | M10    | 25 | 17,0 | 20             | -      | -   | 18,14 €                 | 104,25 €  |
| MHX10-30/B  | MHX10-30/SS/B   | M10    | 30 | 17,0 | 20             | -      | -   | 21,69 €                 | 124,86 €  |
| MHX10-40/B  | MHX10-40/SS/B   | M10    | 40 | 17,0 | 20             | ✓      | -   | 28,67 €                 | 166,23 €  |
| MHX10-50/B  | -               | M10    | 50 | 17,0 | 20             | -      | -   | 35,54 €                 | -         |
| MHX10-60/B  | -               | M10    | 60 | 17,0 | 20             | -      | -   | 43,78 €                 | -         |
| MHX10-70/B  | -               | M10    | 70 | 17,0 | 20             | ✓      | -   | 51,29 €                 | -         |
| MHX12-25/B  | -               | M12    | 25 | 19,0 | 20             | ✓      | -   | 22,74 €                 | -         |
| MHX12-30/B  | MHX12-30/SS/B   | M12    | 30 | 19,0 | 20             | -      | -   | 27,81 €                 | 147,60 €  |
| MHX12-40/B  | MHX12-40/SS/B   | M12    | 40 | 19,0 | 20             | ✓      | -   | 36,48 €                 | 175,29 €  |
| MHX12-50/B  | MHX12-50/SS/B   | M12    | 50 | 19,0 | 20             | ✓      | -   | 45,66 €                 | 218,76 €  |
| MHX12-60/B  | -               | M12    | 60 | 19,0 | 20             | -      | -   | 54,52 €                 | -         |
| MHX12-70/B  | -               | M12    | 70 | 19,0 | 20             | ✓      | -   | 62,84 €                 | -         |

\*Depending on availability - Dimensions in mm

## Our other products



PVL  
Small lobed handle,  
Polyamide




AC  
Strike for toggle latch,  
18mm



NAST  
Cam follower without  
axial guide, With  
interior ring



DER71  
Stainless steel AC  
asynchronous motor  
0.25 à 0.37kW, 0.25  
to 0.37kW

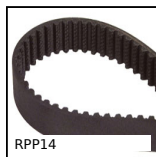

RPP14  
RPP heavy duty  
timing belt, RPP14



GAL22  
Conveyor wheel, Zinc  
plated steel



BPFss  
Pressed stainless  
steel flange bearing,  
Stainless steel



PGMram  
Pull handle Hygienic  
Usit®, Stainless steel  
support washer



BMF  
Knurled knob -  
female, Knurled -  
through threaded



CHAR5050\_Z  
Spring hinge for screw  
mounting, screwed



PM4  
Worm and wheel set,  
Bronze



FBL4004\_K32  
Brush strip per metre,  
Black striated  
polypropylene (PP)

## Complementary products



MHX  
Hexagonal threaded  
sleeve, Hexagonal -  
steel



TIF  
Threaded rod -  
DIN975, Stainless  
steel A2



MHXred  
Reducing sleeve  
male/female,  
Hexagonal - stainless  
steel



TIFss  
Threaded stud -  
DIN976A, Stainless  
steel