

Bow shackle with eye bolt




MLY

Pin diameters 5-20mm

- **Lifting shackle**
- Marked with pin diameter, SWL and CE mark.
- **Material:**
Shackle : Steel Fe430B zinc treated

Info.

- SWL: Safe working load.
The Safe Working Load is calculated by dividing the Breaking Strength by a factor of safety of 5.
- **Not sold individually, please contact us for details.**

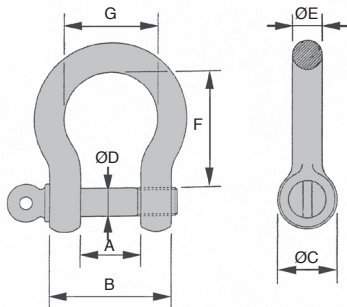

DISCOUNTS

Qty	1+	5+	10+	20+	30+	50+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	Pin ØD	A	B	ØC	ØE	F	G	SWL (kg)	Weight (kg)	Stock*	Price each 1 to 4
MLY1-05	5	8	18	10	5	19	15	100	0,020	✓	2,86 €
MLY1-06	6	12	24	12	6	24	18	160	0,030	✓	2,98 €
MLY1-08	8	15	31	16	8	32	24	250	0,070	✓	3,24 €
MLY1-10	10	18	38	20	10	38	30	400	0,130	✓	4,39 €
MLY1-12	12	22	48	24	12	50	36	630	0,230	✓	8,01 €
MLY1-14	14	24	53	28	15	56	42	800	0,370	✓	9,50 €
MLY1-16	16	27	61	32	17	64	48	1000	0,560	-	11,80 €
MLY1-18	18	36	72	36	18	72	54	1300	0,780	✓	18,09 €
MLY1-20	20	37	78	41	20	79	60	1600	1,090	✓	19,17 €

*Depending on availability - Dimensions in mm

 
HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



TBV
Manual lifting tables,
3kg



PRF JL5
Lip seal for panel,
Door seal - Ø 5mm



T10-BAR
T type tooth bar
stock, T10



DCG
Suction cup, 2.5
bellows, natural
rubber



WING
Manually tightened
wing nut, Stainless
steel DIN 314/315



DP
Dowel pin, Solid ISO
2338



GLT3-46A
Telescopic drawer
with damper,



PDM_PDV
Detectable plastic
palm grip, blue
thermoplastic



RURt
Swivel castor with
central hole,
Polyurethane -
Aluminium rim (Free



BFA
Shaft locking washer,
E clip



P70
Worm and wheel gear
reducer, up to 164
Nm



SCH
Horizontal hook
toggle clamp,
Horizontal Hook
clamp - steel

Complementary products



MLY_SS
Stainless steel bow
shackle with eye bolt,
Stainless steel



MDR
Dee shackle with eye
bolt, Steel