

# Bow shackle with eye bolt




## MLY

## Pin diameters 5-20mm

- **Lifting shackle**
- Marked with pin diameter, SWL and CE mark.
- **Material:**  
Shackle : Steel Fe430B zinc treated

### Info.

- SWL: Safe working load.  
The Safe Working Load is calculated by dividing the Breaking Strength by a factor of safety of 5.
- **Not sold individually, please contact us for details.**

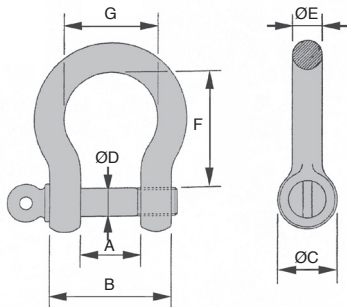

### DISCOUNTS

Qty	1+	5+	10+	20+	30+	50+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	Pin ØD	A	B	ØC	ØE	F	G	SWL (kg)	Weight (kg)	Stock*	Price each 1 to 4
MLY1-05	5	8	18	10	5	19	15	100	0,020	✓	2,86 €
MLY1-06	6	12	24	12	6	24	18	160	0,030	✓	2,98 €
MLY1-08	8	15	31	16	8	32	24	250	0,070	✓	3,24 €
MLY1-10	10	18	38	20	10	38	30	400	0,130	✓	4,39 €
MLY1-12	12	22	48	24	12	50	36	630	0,230	✓	8,01 €
MLY1-14	14	24	53	28	15	56	42	800	0,370	✓	9,50 €
MLY1-16	16	27	61	32	17	64	48	1000	0,560	-	11,80 €
MLY1-18	18	36	72	36	18	72	54	1300	0,780	✓	18,09 €
MLY1-20	20	37	78	41	20	79	60	1600	1,090	✓	19,17 €

\*Depending on availability - Dimensions in mm

**HPC**

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

## Our other products



MRASSeco

Low cost stainless steel quick link, Stainless steel



T2

T type timing belt, T2.5 Steel cored polyurethane



MSP23

Masterplate® glueable insert Ø23, Cylindrical Ø23 with tapped ins...



CHM30

Worm and wheel gear reducer, up to 28 Nm



HTD14M\_85

HTD Heavy duty timing pulley, HTD14 Cast



BTE

Universal tension arm, For standard applications



ADL\_M

Male eye bolt conforms to DIN580, Steel



PW\_PWG1

Wheel - precision range, Bronze



T10\_21N1F

T type timing pulley, Economy range - T10



T5M\_T10M

T type timing belt per metre, T5 Steel cored



CHAM5270SS

Marine hinge for welding/screw



PR85

Articulated foot Ø83, Ø 83

## Complementary products



MLY\_SS

Stainless steel bow shackle with eye bolt, Stainless steel



MDR

Dee shackle with eye bolt, Steel