



# Stainless steel bow shackle with eye bolt

Pin diameters 5-20mm


MLYss

- Lifting shackle
- Material: Stainless steel 316
- No marking on the product

## Info.

- SWL: safe working load.
- The Safe Working Load is calculated by dividing the Breaking Strength by a factor of safety of 5.

stainless steel

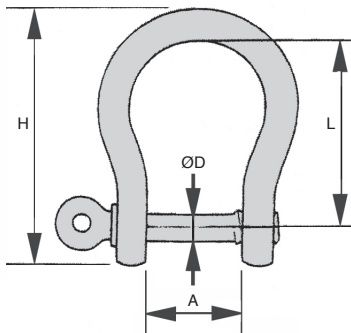

## DISCOUNTS

Qty	1+	5+	10+	20+	30+
Disc.	List	-5%	-10%	-15%	On request

Part number	Pin ØD	A	L	H	SWL (kg)	Weight (kg)	Stock*	Price each 1 to 4
MLY1-05/SS	5	10,0	20,0	30	190	0,015	✓	3,74 €
MLY1-06/SS	6	13,0	26,0	38	360	0,030	✓	3,93 €
MLY1-08/SS	8	17,0	34,0	50	540	0,080	✓	4,95 €
MLY1-10/SS	10	19,0	45,0	65	720	0,130	✓	8,02 €
MLY1-12/SS	12	24,6	54,0	72	1080	0,245	✓	14,53 €
MLY1-14/SS	13	28,0	65,0	91	1260	0,375	✓	19,72 €
MLY1-16/SS	16	33,0	71,0	105	1680	0,450	-	29,38 €
MLY1-20/SS	19	40,0	92,5	133	2400	0,860	-	55,53 €

\*Depending on availability - Dimensions in mm

## Our other products



F7-SF-5M  
Multifunction display,  
Right angled  
mounting bracket



SLVVlok  
Vertical toggle clamp,  
Vertical toggle clamp /  
vertical foot




PW\_PWG15  
Wheel - precision  
range, Bronze



PSP  
Support profile, Panel  
support



 BLHB50  
Right angled gearbox,  
bored shafts, up to 30  
Nm



BCM\_HPBT  
Modular cylindrical  
brush, PBT polyester  
bristles



SSB  
Stainless steel bevel  
gear, 1:1



MSP3815  
Masterplate®  
glueable insert  
rectangular,  
rectangular with



VT  
Vari-Tork® slip  
friction clutch, 0.53 to  
1.32 Nm



PO  
Pull handle - Multi-  
sector, Tapped  
recessed insert



AFSE  
Locking pin with  
interlocking safety  
latch, with



TCC\_SS  
Stainless steel rigging  
screw (hook/hook),  
Stainless steel

## Complementary products



MLY  
Bow shackle with eye  
bolt, Steel



MDR\_SS  
Stainless steel Dee  
shackle with eye bolt,  
Stainless steel