


 

Hexagonal spacer

Bra **Stock**

MPB

Brass

- Male/female pillar
- Material:
nickel plated brass
- Sold by the packet

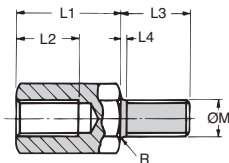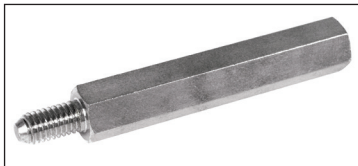

DISCOUNTS

N° packets	1+	5+	20+	100+
Discount	Prix -20%	-30%	On request	

Part number	Thread	ØM	L1	L2	L3	L4	AF	R	Qty. per packet	Stock*	Price per packet
MPB2-5/B	M2	5	3	6	0,70	4	0,10	20	✓	4,98 €	
MPB2-8/B	M2	8	4	6	0,70	4	0,10	20	✓	5,25 €	
MPB2-10/B	M2	10	6	6	0,70	4	0,10	20	✓	5,67 €	
MPB2-12/B	M2	12	8	6	0,70	4	0,10	20	✓	5,94 €	
MPB2-20/B	M2	20	8	6	0,70	4	0,10	20	✓	8,40 €	
MPB2-25/B	M2	25	8	6	0,70	4	0,10	20	-	10,79 €	
MPB2.5-5/B	M2,5	5	3	6	0,80	5	0,10	20	✓	4,85 €	
MPB2.5-8/B	M2,5	8	4	6	0,80	5	0,10	20	✓	5,25 €	
MPB2.5-10/B	M2,5	10	6	6	0,80	5	0,10	20	✓	5,67 €	
MPB2.5-12/B	M2,5	12	8	6	0,80	5	0,10	20	✓	6,30 €	
MPB2.5-15/B	M2,5	15	8	6	0,80	5	0,10	20	✓	6,98 €	
MPB2.5-20/B	M2,5	20	8	6	0,80	5	0,10	20	✓	8,55 €	
MPB2.5-25/B	M2,5	25	8	6	0,80	5	0,10	20	✓	9,49 €	
MPB2.5-30/B	M2,5	30	8	6	0,80	5	0,10	20	✓	11,17 €	
MPB2.5-35/B	M2,5	35	8	6	0,80	5	0,10	20	-	13,42 €	

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15€/min + prix appel

DISCOUNTS

N° packets	1+	5+	20+	100+
Discount	Prix	-20%	-30%	On request

Part number	Thread ØM	L1	L2	L3	L4	AF	R	Qty. per packet	Stock*	Price per packet
MPB3-5/B	M3	5	3	8	0,90	5	0,10	20	✓	4,59 €
MPB3-8/B	M3	8	4	8	0,90	5	0,10	20	✓	4,92 €
MPB3-10/B	M3	10	6	8	0,90	5	0,10	20	✓	5,25 €
MPB3-12/B	M3	12	8	8	0,90	5	0,10	20	-	5,67 €
MPB3-15/B	M3	15	8	8	0,90	5	0,10	20	✓	6,21 €
MPB3-18/B	M3	18	8	8	0,90	5	0,10	20	✓	6,98 €
MPB3-20/B	M3	20	8	8	0,90	5	0,10	20	✓	7,50 €
MPB3-25/B	M3	25	10	10	0,90	5	0,10	20	✓	8,68 €
MPB3-30/B	M3	30	10	10	0,90	5	0,10	20	✓	10,00 €
MPB3-35/B	M3	35	10	10	0,90	5	0,10	20	✓	12,63 €
MPB3-40/B	M3	40	10	10	0,90	5	0,10	20	-	13,93 €
MPB3-45/B	M3	45	10	10	0,90	5	0,10	20	-	15,40 €
MPB3-60/B	M3	60	10	10	0,90	5	0,10	20	-	20,01 €
MPB3-70/B	M3	70	10	10	0,90	5	0,10	20	✓	22,35 €
MPB4-8/B	M4	8	4	8	1,20	7	0,20	20	✓	7,25 €
MPB4-10/B	M4	10	6	8	1,20	7	0,20	20	✓	7,62 €
MPB4-12/B	M4	12	8	8	1,20	7	0,20	20	✓	8,02 €
MPB4-15/B	M4	15	8	8	1,20	7	0,20	20	-	8,97 €
MPB4-18/B	M4	18	8	8	1,20	7	0,20	20	-	10,00 €
MPB4-20/B	M4	20	8	8	1,20	7	0,20	20	✓	10,79 €
MPB4-25/B	M4	25	10	10	1,20	7	0,20	20	✓	12,49 €
MPB4-30/B	M4	30	10	10	1,20	7	0,20	20	✓	14,47 €
MPB4-35/B	M4	35	10	10	1,20	7	0,20	20	-	18,02 €
MPB4-45/B	M4	45	10	10	1,20	7	0,20	20	✓	22,21 €
MPB4-50/B	M4	50	10	10	1,20	7	0,20	20	✓	23,92 €
MPB4-80/B	M4	80	10	10	1,20	7	0,20	20	✓	36,41 €
MPB5-5/B	M5	5	3	8	1,40	8	0,20	20	-	On request
MPB5-8/B	M5	8	4	8	1,40	8	0,20	20	-	9,49 €
MPB5-10/B	M5	10	6	8	1,40	8	0,20	20	✓	9,60 €
MPB5-12/B	M5	12	8	8	1,40	8	0,20	20	✓	10,39 €
MPB5-15/B	M5	15	8	8	1,40	8	0,20	20	✓	11,57 €
MPB5-20/B	M5	20	8	8	1,40	8	0,20	20	✓	14,19 €
MPB5-25/B	M5	25	10	10	1,40	8	0,20	20	✓	16,71 €
MPB5-30/B	M5	30	10	10	1,40	8	0,20	20	✓	20,26 €
MPB5-35/B	M5	35	10	10	1,40	8	0,20	20	-	22,46 €
MPB5-40/B	M5	40	10	10	1,40	8	0,20	20	✓	24,44 €
MPB5-50/B	M5	50	10	10	1,40	8	0,20	20	-	29,20 €
MPB5-60/B	M5	60	10	10	1,40	8	0,20	20	✓	34,72 €
MPB5-70/B	M5	70	10	10	1,40	8	0,20	20	-	39,05 €
MPB5-80/B	M5	80	10	10	1,40	8	0,20	20	-	44,98 €

*Depending on availability - Dimensions in mm

Our other products



SSB

Stainless steel bevel gear, 1:1



PSG25

Spur gear - precision range, Pre-hardened Steel 35NCD6



PO

Pull handle - Multi-sector, Smooth hole



EHD04

Internal epicyclic servo reducers, from 3.4 to 7 Nm



ACM_DZ

Clip for bonnet fastener, Clip



SDG_SS

Universal adjustable guide support bracket, Stainless steel




PTRSS

Idler chain sprocket, For hostile environments



DOG316

 Motor-gearbox 12V and 24V DC, from 1.5 to 2 Nm



CHTRB

Single and dual output gearboxes, Up to 87,3 Nm




NCT

Square tube connector, Fixed angle



CNA-CNG

Right angled mounting plate, Right angled mounting plate for clevis

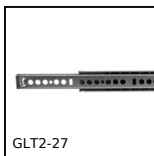

GLT2-27

Telescopic drawer runners for groove mounting, Partial extension

Complementary products



MPE

Hexagonal spacer, Steel



HSE-HSB

Hexagonal spacer, Brass