


 

Hexagonal spacer



MPB

Brass

- Male/female pillar
- Material:
nickel plated brass
- Sold by the packet

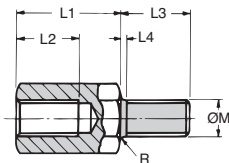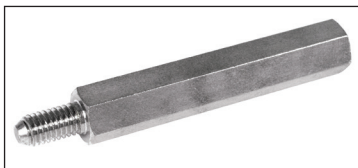

DISCOUNTS

N° packets	1+	5+	20+	100+
Discount	Prix -20%	-30%	On request	

Part number	Thread	ØM	L1	L2	L3	L4	AF	R	Qty. per packet	Stock*	Price per packet
MPB2-5/B	M2		5	3	6	0,70	4	0,10	20	✓	4,98 €
MPB2-8/B	M2		8	4	6	0,70	4	0,10	20	✓	5,25 €
MPB2-10/B	M2		10	6	6	0,70	4	0,10	20	✓	5,67 €
MPB2-12/B	M2		12	8	6	0,70	4	0,10	20	✓	5,94 €
MPB2-20/B	M2		20	8	6	0,70	4	0,10	20	✓	8,40 €
MPB2-25/B	M2		25	8	6	0,70	4	0,10	20	-	10,79 €
MPB2.5-5/B	M2,5		5	3	6	0,80	5	0,10	20	✓	4,85 €
MPB2.5-8/B	M2,5		8	4	6	0,80	5	0,10	20	✓	5,25 €
MPB2.5-10/B	M2,5		10	6	6	0,80	5	0,10	20	✓	5,67 €
MPB2.5-12/B	M2,5		12	8	6	0,80	5	0,10	20	✓	6,30 €
MPB2.5-15/B	M2,5		15	8	6	0,80	5	0,10	20	✓	6,98 €
MPB2.5-20/B	M2,5		20	8	6	0,80	5	0,10	20	✓	8,55 €
MPB2.5-25/B	M2,5		25	8	6	0,80	5	0,10	20	✓	9,49 €
MPB2.5-30/B	M2,5		30	8	6	0,80	5	0,10	20	✓	11,17 €
MPB2.5-35/B	M2,5		35	8	6	0,80	5	0,10	20	-	13,42 €

*Depending on availability - Dimensions in mm

DISCOUNTS

N° packets	1+	5+	20+	100+
Discount	Prix	-20%	-30%	On request

Part number	Thread ØM	L1	L2	L3	L4	AF	R	Qty. per packet	Stock*	Price per packet
MPB3-5/B	M3	5	3	8	0,90	5	0,10	20	✓	4,59 €
MPB3-8/B	M3	8	4	8	0,90	5	0,10	20	✓	4,92 €
MPB3-10/B	M3	10	6	8	0,90	5	0,10	20	✓	5,25 €
MPB3-12/B	M3	12	8	8	0,90	5	0,10	20	-	5,67 €
MPB3-15/B	M3	15	8	8	0,90	5	0,10	20	✓	6,21 €
MPB3-18/B	M3	18	8	8	0,90	5	0,10	20	✓	6,98 €
MPB3-20/B	M3	20	8	8	0,90	5	0,10	20	✓	7,50 €
MPB3-25/B	M3	25	10	10	0,90	5	0,10	20	✓	8,68 €
MPB3-30/B	M3	30	10	10	0,90	5	0,10	20	✓	10,00 €
MPB3-35/B	M3	35	10	10	0,90	5	0,10	20	✓	12,63 €
MPB3-40/B	M3	40	10	10	0,90	5	0,10	20	-	13,93 €
MPB3-45/B	M3	45	10	10	0,90	5	0,10	20	-	15,40 €
MPB3-60/B	M3	60	10	10	0,90	5	0,10	20	-	20,01 €
MPB3-70/B	M3	70	10	10	0,90	5	0,10	20	✓	22,35 €
MPB4-8/B	M4	8	4	8	1,20	7	0,20	20	✓	7,25 €
MPB4-10/B	M4	10	6	8	1,20	7	0,20	20	✓	7,62 €
MPB4-12/B	M4	12	8	8	1,20	7	0,20	20	✓	8,02 €
MPB4-15/B	M4	15	8	8	1,20	7	0,20	20	-	8,97 €
MPB4-18/B	M4	18	8	8	1,20	7	0,20	20	-	10,00 €
MPB4-20/B	M4	20	8	8	1,20	7	0,20	20	✓	10,79 €
MPB4-25/B	M4	25	10	10	1,20	7	0,20	20	✓	12,49 €
MPB4-30/B	M4	30	10	10	1,20	7	0,20	20	✓	14,47 €
MPB4-35/B	M4	35	10	10	1,20	7	0,20	20	-	18,02 €
MPB4-45/B	M4	45	10	10	1,20	7	0,20	20	✓	22,21 €
MPB4-50/B	M4	50	10	10	1,20	7	0,20	20	✓	23,92 €
MPB4-80/B	M4	80	10	10	1,20	7	0,20	20	✓	36,41 €
MPB5-5/B	M5	5	3	8	1,40	8	0,20	20	-	On request
MPB5-8/B	M5	8	4	8	1,40	8	0,20	20	-	9,49 €
MPB5-10/B	M5	10	6	8	1,40	8	0,20	20	✓	9,60 €
MPB5-12/B	M5	12	8	8	1,40	8	0,20	20	✓	10,39 €
MPB5-15/B	M5	15	8	8	1,40	8	0,20	20	✓	11,57 €
MPB5-20/B	M5	20	8	8	1,40	8	0,20	20	✓	14,19 €
MPB5-25/B	M5	25	10	10	1,40	8	0,20	20	✓	16,71 €
MPB5-30/B	M5	30	10	10	1,40	8	0,20	20	✓	20,26 €
MPB5-35/B	M5	35	10	10	1,40	8	0,20	20	-	22,46 €
MPB5-40/B	M5	40	10	10	1,40	8	0,20	20	✓	24,44 €
MPB5-50/B	M5	50	10	10	1,40	8	0,20	20	-	29,20 €
MPB5-60/B	M5	60	10	10	1,40	8	0,20	20	✓	34,72 €
MPB5-70/B	M5	70	10	10	1,40	8	0,20	20	-	39,05 €
MPB5-80/B	M5	80	10	10	1,40	8	0,20	20	-	44,98 €

*Depending on availability - Dimensions in mm

Our other products



Adjustable latch clamp with strike plate, Stroke from 96mm to 121,7mm



Slotted spring plunger with ball tip, Stainless steel 303



Ball transfer unit plain fit, High



Adjustable latch clamp with strike plate, Stroke from 82mm to 92mm




Decorative asymmetric screwed hinge, Polyamide



Standard aluminium profile, 45 x 32 mm



Domino 120 adjustable slide, Slide DOMILINE 120 with counter and han...

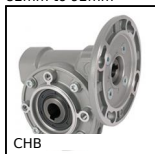

Worm and wheel gear reducer, up to 73 Nm



Retractable castor for aluminium profile,



Roll-Ring® chain tensioner, Roll-Ring®



Washer - DIN125, Brass



Bellows cover, Accessory:

Complementary products



Hexagonal spacer, Steel



Hexagonal spacer, Brass