

Hexagonal spacer

Ste Bra Stock


HSE
HSB

Steel or Brass

- Female/female pillar
- Material: Zn3-5BL steel zinc-plated by electrolysis or brass

Info.

- Sold by the packet

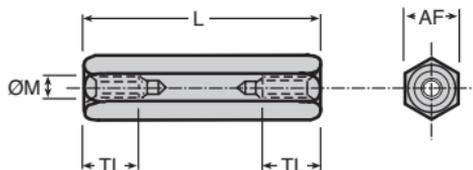

DISCOUNTS

| | | | | |
|------------|------|------|------|------------|
| N° packets | 1+ | 5+ | 20+ | 100+ |
| Discount | Prix | -20% | -30% | On request |

| Part number | Steel | Brass | Thread | ØM | L | TL | AF | Qty. per packet | Stock* | | Price per packet | |
|-------------|-------|-------------|--------|----|----|----|----|-----------------|--------|------------|------------------|-------|
| | | | | | | | | | Steel | Brass | Steel | Brass |
| - | | HSB2-5/B | M2 | 5 | 5 | 4 | 20 | - | ✓ | - | 4.73 € | |
| - | | HSB2-8/B | M2 | 8 | 8 | 4 | 20 | - | ✓ | - | 5.09 € | |
| - | | HSB2-10/B | M2 | 10 | 10 | 4 | 20 | - | ✓ | - | 5.48 € | |
| - | | HSB2-12/B | M2 | 12 | 12 | 4 | 20 | - | ✓ | - | 6.00 € | |
| - | | HSB2-15/B | M2 | 15 | 15 | 4 | 20 | - | ✓ | - | 6.91 € | |
| - | | HSB2-20/B | M2 | 20 | 20 | 4 | 20 | - | - | - | On request | |
| - | | HSB2-25/B | M2 | 25 | 8 | 4 | 20 | - | ✓ | - | 15.61 € | |
| - | | HSB2-35/B | M2 | 35 | 8 | 4 | 20 | - | ✓ | - | 21.38 € | |
| - | | HSB2-40/B | M2 | 40 | 8 | 4 | 20 | - | - | - | 22.84 € | |
| HSE2.5-5/B | | HSB2.5-5/B | M2,5 | 5 | 5 | 5 | 20 | - | ✓ | On request | 4.37 € | |
| - | | HSB2.5-8/B | M2,5 | 8 | 8 | 5 | 20 | - | ✓ | - | 4.92 € | |
| HSE2.5-10/B | | HSB2.5-10/B | M2,5 | 10 | 10 | 5 | 20 | - | ✓ | 7.31 € | 5.38 € | |
| - | | HSB2.5-12/B | M2,5 | 12 | 12 | 5 | 20 | - | ✓ | - | 5.81 € | |
| HSE2.5-15/B | | - | M2,5 | 15 | 15 | 5 | 20 | - | - | 9.19 € | - | |
| HSE2.5-20/B | | HSB2.5-20/B | M2,5 | 20 | 20 | 5 | 20 | - | - | 11.59 € | 8.36 € | |
| HSE2.5-30/B | | HSB2.5-30/B | M2,5 | 30 | 10 | 5 | 20 | - | - | On request | 11.46 € | |
| - | | HSB3-5/B | M3 | 5 | 5 | 5 | 20 | - | ✓ | - | 4.01 € | |
| HSE3-8/B | | HSB3-8/B | M3 | 8 | 8 | 5 | 20 | ✓ | ✓ | 4.79 € | 4.51 € | |
| HSE3-10/B | | HSB3-10/B | M3 | 10 | 10 | 5 | 20 | ✓ | ✓ | 5.10 € | 4.92 € | |
| HSE3-12/B | | HSB3-12/B | M3 | 12 | 12 | 5 | 20 | ✓ | - | 5.43 € | 5.48 € | |
| HSE3-15/B | | HSB3-15/B | M3 | 15 | 15 | 5 | 20 | ✓ | ✓ | 5.95 € | 6.00 € | |
| HSE3-18/B | | HSB3-18/B | M3 | 18 | 18 | 5 | 20 | - | ✓ | 6.67 € | 6.91 € | |
| HSE3-20/B | | HSB3-20/B | M3 | 20 | 20 | 5 | 20 | ✓ | ✓ | 7.34 € | 7.73 € | |
| HSE3-25/B | | HSB3-25/B | M3 | 25 | 10 | 5 | 20 | ✓ | ✓ | 7.27 € | 9.08 € | |
| HSE3-30/B | | HSB3-30/B | M3 | 30 | 10 | 5 | 20 | ✓ | ✓ | 7.51 € | 10.53 € | |
| HSE3-35/B | | HSB3-35/B | M3 | 35 | 10 | 5 | 20 | - | - | 7.94 € | 12.53 € | |
| HSE3-40/B | | HSB3-40/B | M3 | 40 | 10 | 5 | 20 | ✓ | - | 8.32 € | 15.76 € | |
| HSE3-45/B | | HSB3-45/B | M3 | 45 | 10 | 5 | 20 | - | - | 8.71 € | 17.55 € | |
| HSE3-50/B | | HSB3-50/B | M3 | 50 | 10 | 5 | 20 | - | - | 14.70 € | 12.87 € | |
| HSE3-55/B | | - | M3 | 55 | 10 | 5 | 20 | - | - | 15.38 € | - | |
| HSE3-60/B | | HSB3-60/B | M3 | 60 | 10 | 5 | 20 | ✓ | - | 15.98 € | 22.84 € | |
| HSE3-70/B | | - | M3 | 70 | 10 | 5 | 20 | - | - | 17.56 € | - | |

*Depending on availability - Dimensions in mm

DISCOUNTS

| N° packets | 1+ | 5+ | 20+ | 100+ |
|------------|-----------|------|------------|------|
| Discount | Prix -20% | -30% | On request | |

| Part number | | Thread ØM | L | TL | AF | Qty. per packet | Stock* | | Price per packet | |
|-------------|-----------|--------------|----|----|----|-----------------------|--------|-------|------------------|---------|
| Steel | Brass | | | | | | Steel | Brass | Steel | Brass |
| HSE4-8/B | HSB4-8/B | M4 | 8 | 8 | 7 | 20 | ✓ | ✓ | 5,86 € | 6,00 € |
| HSE4-10/B | HSB4-10/B | M4 | 10 | 10 | 7 | 20 | ✓ | - | 6,06 € | 6,42 € |
| HSE4-12/B | - | M4 | 12 | 12 | 7 | 20 | ✓ | - | 6,51 € | - |
| HSE4-15/B | HSB4-15/B | M4 | 15 | 15 | 7 | 20 | ✓ | ✓ | 7,19 € | 8,56 € |
| HSE4-20/B | HSB4-20/B | M4 | 20 | 20 | 7 | 20 | ✓ | ✓ | 9,00 € | 11,10 € |
| HSE4-25/B | HSB4-25/B | M4 | 25 | 10 | 7 | 20 | ✓ | - | 9,25 € | 12,91 € |
| HSE4-30/B | HSB4-30/B | M4 | 30 | 10 | 7 | 20 | ✓ | ✓ | 10,08 € | 15,27 € |
| HSE4-35/B | HSB4-35/B | M4 | 35 | 10 | 7 | 20 | ✓ | - | 10,79 € | 18,35 € |
| HSE4-40/B | HSB4-40/B | M4 | 40 | 10 | 7 | 20 | ✓ | ✓ | 11,37 € | 22,84 € |
| HSE4-45/B | HSB4-45/B | M4 | 45 | 10 | 7 | 20 | ✓ | ✓ | 11,74 € | 25,54 € |
| HSE4-50/B | - | M4 | 50 | 10 | 7 | 20 | ✓ | - | 17,95 € | - |
| HSE4-55/B | - | M4 | 55 | 10 | 7 | 20 | - | - | 18,85 € | - |
| HSE4-60/B | - | M4 | 60 | 10 | 7 | 20 | ✓ | - | 19,76 € | - |
| HSE4-70/B | - | M4 | 70 | 10 | 7 | 20 | - | - | 21,64 € | - |
| HSE4-80/B | - | M4 | 80 | 10 | 7 | 20 | ✓ | - | 23,62 € | - |
| HSE5-10/B | HSB5-10/B | M5 | 10 | 10 | 8 | 20 | - | - | 6,95 € | 7,85 € |
| HSE5-12/B | - | M5 | 12 | 12 | 8 | 20 | ✓ | - | 8,53 € | - |
| HSE5-15/B | HSB5-15/B | M5 | 15 | 15 | 8 | 20 | ✓ | - | 9,39 € | 10,55 € |
| HSE5-20/B | HSB5-20/B | M5 | 20 | 20 | 8 | 20 | ✓ | - | 13,43 € | 13,28 € |
| HSE5-25/B | HSB5-25/B | M5 | 25 | 10 | 8 | 20 | ✓ | - | 14,50 € | 15,64 € |
| HSE5-30/B | HSB5-30/B | M5 | 30 | 10 | 8 | 20 | ✓ | ✓ | 15,74 € | 18,35 € |
| HSE5-35/B | HSB5-35/B | M5 | 35 | 10 | 8 | 20 | ✓ | - | 16,48 € | 23,75 € |
| HSE5-40/B | - | M5 | 40 | 10 | 8 | 20 | ✓ | - | 17,41 € | - |
| HSE5-45/B | - | M5 | 45 | 10 | 8 | 20 | - | - | 18,62 € | - |
| HSE5-50/B | HSB5-50/B | M5 | 50 | 10 | 8 | 20 | ✓ | - | 20,17 € | 32,79 € |
| - | HSB5-55/B | M5 | 55 | 10 | 8 | 20 | - | - | - | 36,42 € |
| HSE5-60/B | HSB5-60/B | M5 | 60 | 10 | 8 | 20 | - | ✓ | 22,84 € | 39,97 € |
| HSE5-70/B | HSB5-70/B | M5 | 70 | 10 | 8 | 20 | ✓ | - | 25,07 € | 47,23 € |
| HSE6-10/B | - | M6 | 10 | 10 | 10 | 20 | ✓ | - | 18,01 € | - |
| HSE6-12/B | - | M6 | 12 | 12 | 10 | 20 | ✓ | - | 18,41 € | - |
| HSE6-15/B | - | M6 | 15 | 15 | 10 | 20 | ✓ | - | 19,45 € | - |
| HSE6-18/B | - | M6 | 18 | 18 | 10 | 20 | ✓ | - | 20,60 € | - |
| HSE6-20/B | - | M6 | 20 | 20 | 10 | 20 | ✓ | - | 21,43 € | - |
| HSE6-25/B | - | M6 | 25 | 25 | 10 | 20 | ✓ | - | 23,49 € | - |
| HSE6-30/B | - | M6 | 30 | 13 | 10 | 20 | ✓ | - | 24,50 € | - |
| HSE6-35/B | - | M6 | 35 | 13 | 10 | 20 | ✓ | - | 25,58 € | - |
| HSE6-40/B | - | M6 | 40 | 13 | 10 | 20 | ✓ | - | 26,62 € | - |
| HSE6-45/B | - | M6 | 45 | 13 | 10 | 20 | ✓ | - | 27,79 € | - |
| HSE6-50/B | - | M6 | 50 | 13 | 10 | 20 | ✓ | - | 29,05 € | - |
| HSE6-55/B | - | M6 | 55 | 13 | 10 | 20 | ✓ | - | 30,24 € | - |
| HSE6-60/B | - | M6 | 60 | 13 | 10 | 20 | ✓ | - | 32,12 € | - |
| HSE6-70/B | - | M6 | 70 | 13 | 10 | 20 | - | - | 34,73 € | - |
| HSE6-80/B | - | M6 | 80 | 13 | 10 | 20 | ✓ | - | 36,08 € | - |

*Depending on availability - Dimensions in mm

Hexagonal spacer

Stock **Ste**


MPE

Steel

- Male/female pillar
- Material: Zn3-5BL steel zinc-plated by electrolysis

Info.

- Sold by the packet

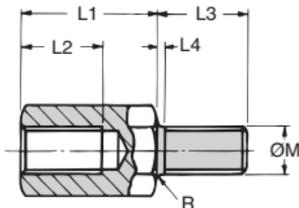

DISCOUNTS

| | | | | |
|------------|-----------|------|------------|------|
| N° packets | 1+ | 5+ | 20+ | 100+ |
| Discount | Prix -20% | -30% | On request | |

| Part number | Thread | ØM | L1 | L2 | L3 | L4 | AF | R | Qty. per packet | Price per packet | |
|-------------|--------|----|----|----|------|----|------|----|-----------------|------------------|-------|
| | | | | | | | | | | Stock | Price |
| MPE3-5/B | M3 | 5 | 3 | 8 | 0,90 | 5 | 0,10 | 20 | ✓ | 4,02 € | |
| MPE3-8/B | M3 | 8 | 4 | 8 | 0,90 | 5 | 0,10 | 20 | ✓ | 5,43 € | |
| MPE3-10/B | M3 | 10 | 6 | 8 | 0,90 | 5 | 0,10 | 20 | ✓ | 5,91 € | |
| MPE3-12/B | M3 | 12 | 8 | 8 | 0,90 | 5 | 0,10 | 20 | ✓ | 6,00 € | |
| MPE3-15/B | M3 | 15 | 8 | 8 | 0,90 | 5 | 0,10 | 20 | ✓ | 6,22 € | |
| MPE3-18/B | M3 | 18 | 8 | 8 | 0,90 | 5 | 0,10 | 20 | ✓ | 6,47 € | |
| MPE3-20/B | M3 | 20 | 8 | 8 | 0,90 | 5 | 0,10 | 20 | ✓ | 6,55 € | |
| MPE3-25/B | M3 | 25 | 10 | 10 | 0,90 | 5 | 0,10 | 20 | ✓ | 7,68 € | |
| MPE3-30/B | M3 | 30 | 10 | 10 | 0,90 | 5 | 0,10 | 20 | ✓ | 8,07 € | |
| MPE3-35/B | M3 | 35 | 10 | 10 | 0,90 | 5 | 0,10 | 20 | ✓ | 8,49 € | |
| MPE3-40/B | M3 | 40 | 10 | 10 | 0,90 | 5 | 0,10 | 20 | ✓ | 13,80 € | |
| MPE3-45/B | M3 | 45 | 10 | 10 | 0,90 | 5 | 0,10 | 20 | ✓ | 15,10 € | |
| MPE3-50/B | M3 | 50 | 10 | 10 | 0,90 | 5 | 0,10 | 20 | ✓ | 16,43 € | |
| MPE3-55/B | M3 | 55 | 10 | 10 | 0,90 | 5 | 0,10 | 20 | ✓ | 17,33 € | |
| MPE3-60/B | M3 | 60 | 10 | 10 | 0,90 | 5 | 0,10 | 20 | - | 18,40 € | |
| MPE3-70/B | M3 | 70 | 10 | 10 | 0,90 | 5 | 0,10 | 20 | - | 20,03 € | |
| MPE3-80/B | M3 | 80 | 10 | 10 | 0,90 | 5 | 0,10 | 20 | - | 21,31 € | |
| MPE4-5/B | M4 | 5 | 3 | 8 | 1,20 | 7 | 0,20 | 20 | ✓ | 7,11 € | |
| MPE4-8/B | M4 | 8 | 4 | 8 | 1,20 | 7 | 0,20 | 20 | ✓ | 7,70 € | |
| MPE4-10/B | M4 | 10 | 6 | 8 | 1,20 | 7 | 0,20 | 20 | ✓ | 7,05 € | |
| MPE4-12/B | M4 | 12 | 8 | 8 | 1,20 | 7 | 0,20 | 20 | ✓ | 7,67 € | |
| MPE4-15/B | M4 | 15 | 8 | 8 | 1,20 | 7 | 0,20 | 20 | ✓ | 7,77 € | |
| MPE4-18/B | M4 | 18 | 8 | 8 | 1,20 | 7 | 0,20 | 20 | - | 8,56 € | |

*Depending on availability - Dimensions in mm

| Part number | Thread | | L1 | L2 | L3 | L4 | AF | R | Qty. per packet | Stock* | Price per packet |
|-------------|--------|----|----|----|------|----|------|----|-----------------|---------|------------------|
| | OM | OM | | | | | | | | | |
| MPE4-20/B | M4 | 20 | 8 | 8 | 1,20 | 7 | 0,20 | 20 | ✓ | 8,87 € | |
| MPE4-25/B | M4 | 25 | 10 | 10 | 1,20 | 7 | 0,20 | 20 | ✓ | 10,60 € | |
| MPE4-30/B | M4 | 30 | 10 | 10 | 1,20 | 7 | 0,20 | 20 | ✓ | 11,41 € | |
| MPE4-35/B | M4 | 35 | 10 | 10 | 1,20 | 7 | 0,20 | 20 | ✓ | 12,20 € | |
| MPE4-40/B | M4 | 40 | 10 | 10 | 1,20 | 7 | 0,20 | 20 | ✓ | 17,86 € | |
| MPE4-45/B | M4 | 45 | 10 | 10 | 1,20 | 7 | 0,20 | 20 | ✓ | 17,92 € | |
| MPE4-50/B | M4 | 50 | 10 | 10 | 1,20 | 7 | 0,20 | 20 | ✓ | 20,39 € | |
| MPE4-55/B | M4 | 55 | 10 | 10 | 1,20 | 7 | 0,20 | 20 | - | 21,67 € | |
| MPE4-60/B | M4 | 60 | 10 | 10 | 1,20 | 7 | 0,20 | 20 | ✓ | 22,97 € | |
| MPE4-70/B | M4 | 70 | 10 | 10 | 1,20 | 7 | 0,20 | 20 | ✓ | 26,07 € | |
| MPE4-80/B | M4 | 80 | 10 | 10 | 1,20 | 7 | 0,20 | 20 | ✓ | 28,25 € | |
| MPE5-5/B | M5 | 5 | 3 | 8 | 1,40 | 8 | 0,20 | 20 | - | 12,01 € | |
| MPE5-8/B | M5 | 8 | 4 | 8 | 1,40 | 8 | 0,20 | 20 | - | 12,01 € | |
| MPE5-10/B | M5 | 10 | 6 | 8 | 1,40 | 8 | 0,20 | 20 | ✓ | 12,01 € | |
| MPE5-12/B | M5 | 12 | 8 | 8 | 1,40 | 8 | 0,20 | 20 | ✓ | 12,54 € | |
| MPE5-15/B | M5 | 15 | 8 | 8 | 1,40 | 8 | 0,20 | 20 | ✓ | 13,18 € | |
| MPE5-18/B | M5 | 18 | 8 | 8 | 1,40 | 8 | 0,20 | 20 | - | 13,90 € | |
| MPE5-20/B | M5 | 20 | 8 | 8 | 1,40 | 8 | 0,20 | 20 | ✓ | 14,50 € | |
| MPE5-25/B | M5 | 25 | 10 | 10 | 1,40 | 8 | 0,20 | 20 | ✓ | 15,80 € | |
| MPE5-30/B | M5 | 30 | 10 | 10 | 1,40 | 8 | 0,20 | 20 | ✓ | 16,88 € | |
| MPE5-35/B | M5 | 35 | 10 | 10 | 1,40 | 8 | 0,20 | 20 | ✓ | 18,65 € | |
| MPE5-40/B | M5 | 40 | 10 | 10 | 1,40 | 8 | 0,20 | 20 | ✓ | 20,39 € | |
| MPE5-45/B | M5 | 45 | 10 | 10 | 1,40 | 8 | 0,20 | 20 | ✓ | 21,60 € | |
| MPE5-50/B | M5 | 50 | 10 | 10 | 1,40 | 8 | 0,20 | 20 | ✓ | 22,92 € | |
| MPE5-55/B | M5 | 55 | 10 | 10 | 1,40 | 8 | 0,20 | 20 | - | 24,24 € | |
| MPE5-60/B | M5 | 60 | 10 | 10 | 1,40 | 8 | 0,20 | 20 | ✓ | 25,76 € | |
| MPE5-70/B | M5 | 70 | 10 | 10 | 1,40 | 8 | 0,20 | 20 | - | 28,98 € | |
| MPE5-80/B | M5 | 80 | 10 | 10 | 1,40 | 8 | 0,20 | 20 | ✓ | 34,09 € | |
| MPE6-10/B | M6 | 10 | 6 | 12 | 2,10 | 10 | 0,25 | 20 | ✓ | 17,86 € | |
| MPE6-12/B | M6 | 12 | 8 | 12 | 2,10 | 10 | 0,25 | 20 | ✓ | 18,01 € | |
| MPE6-15/B | M6 | 15 | 8 | 12 | 2,10 | 10 | 0,25 | 20 | ✓ | 18,86 € | |
| MPE6-18/B | M6 | 18 | 12 | 12 | 2,10 | 10 | 0,25 | 20 | ✓ | 19,42 € | |
| MPE6-20/B | M6 | 20 | 13 | 12 | 2,10 | 10 | 0,25 | 20 | ✓ | 20,19 € | |
| MPE6-25/B | M6 | 25 | 13 | 12 | 2,10 | 10 | 0,25 | 20 | ✓ | 22,06 € | |
| MPE6-30/B | M6 | 30 | 13 | 12 | 2,10 | 10 | 0,25 | 20 | ✓ | 23,16 € | |
| MPE6-35/B | M6 | 35 | 13 | 12 | 2,10 | 10 | 0,25 | 20 | ✓ | 24,24 € | |
| MPE6-40/B | M6 | 40 | 13 | 12 | 2,10 | 10 | 0,25 | 20 | ✓ | 25,36 € | |
| MPE6-45/B | M6 | 45 | 13 | 12 | 2,10 | 10 | 0,25 | 20 | ✓ | 26,57 € | |
| MPE6-50/B | M6 | 50 | 13 | 12 | 2,10 | 10 | 0,25 | 20 | ✓ | 28,09 € | |
| MPE6-55/B | M6 | 55 | 13 | 12 | 2,10 | 10 | 0,25 | 20 | ✓ | 29,26 € | |
| MPE6-60/B | M6 | 60 | 13 | 12 | 2,10 | 10 | 0,25 | 20 | ✓ | 30,33 € | |
| MPE6-70/B | M6 | 70 | 13 | 12 | 2,10 | 10 | 0,25 | 20 | ✓ | 33,04 € | |
| MPE6-80/B | M6 | 80 | 13 | 12 | 2,10 | 10 | 0,25 | 20 | ✓ | 35,26 € | |

*Depending on availability - Dimensions in mm

Hexagonal spacer





MPB

Brass

- Male/female pillar
- Material:
nickel plated brass

Info.

- Sold by the packet

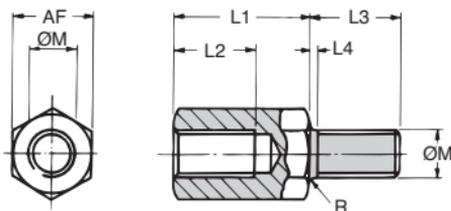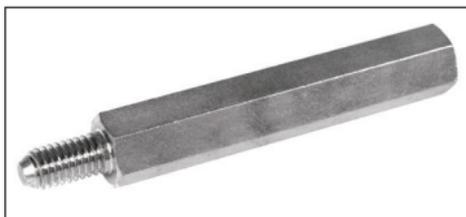

DISCOUNTS

| | | | | |
|------------|------|------|------|------------|
| N° packets | 1+ | 5+ | 20+ | 100+ |
| Discount | Prix | -20% | -30% | On request |

| Part number | Thread | ØM | L1 | L2 | L3 | L4 | AF | R | Qty. per packet | Stock* | Price per packet |
|-------------|--------|----|----|----|------|----|------|----|-----------------|---------|------------------|
| MPB2-5/B | M2 | 5 | 3 | 6 | 0,70 | 4 | 0,10 | 20 | ✓ | 5,81 € | |
| MPB2-8/B | M2 | 8 | 4 | 6 | 0,70 | 4 | 0,10 | 20 | ✓ | 6,18 € | |
| MPB2-10/B | M2 | 10 | 6 | 6 | 0,70 | 4 | 0,10 | 20 | - | 6,75 € | |
| MPB2-12/B | M2 | 12 | 8 | 6 | 0,70 | 4 | 0,10 | 20 | ✓ | 7,11 € | |
| MPB2-20/B | M2 | 20 | 8 | 6 | 0,70 | 4 | 0,10 | 20 | ✓ | 10,53 € | |
| MPB2-25/B | M2 | 25 | 8 | 6 | 0,70 | 4 | 0,10 | 20 | - | 13,80 € | |
| MPB2.5-5/B | M2,5 | 5 | 3 | 6 | 0,80 | 5 | 0,10 | 20 | ✓ | 5,62 € | |
| MPB2.5-8/B | M2,5 | 8 | 4 | 6 | 0,80 | 5 | 0,10 | 20 | ✓ | 6,18 € | |
| MPB2.5-10/B | M2,5 | 10 | 6 | 6 | 0,80 | 5 | 0,10 | 20 | ✓ | 6,75 € | |
| MPB2.5-12/B | M2,5 | 12 | 8 | 6 | 0,80 | 5 | 0,10 | 20 | ✓ | 7,63 € | |
| MPB2.5-15/B | M2,5 | 15 | 8 | 6 | 0,80 | 5 | 0,10 | 20 | ✓ | 8,55 € | |
| MPB2.5-20/B | M2,5 | 20 | 8 | 6 | 0,80 | 5 | 0,10 | 20 | ✓ | 10,73 € | |
| MPB2.5-25/B | M2,5 | 25 | 8 | 6 | 0,80 | 5 | 0,10 | 20 | ✓ | 12,01 € | |
| MPB2.5-30/B | M2,5 | 30 | 8 | 6 | 0,80 | 5 | 0,10 | 20 | ✓ | 14,33 € | |
| MPB2.5-35/B | M2,5 | 35 | 8 | 6 | 0,80 | 5 | 0,10 | 20 | - | 17,41 € | |

*Depending on availability - Dimensions in mm

DISCOUNTS

| N° packets | 1+ | 5+ | 20+ | 100+ |
|------------|------|------|------|------------|
| Discount | Prix | -20% | -30% | On request |

| Part number | Thread ØM | L1 | L2 | L3 | L4 | AF | R | Qty. per packet | Stock* | Price per packet |
|-------------|--------------|----|----|----|------|----|------|--------------------|--------|---------------------|
| MPB3-5/B | M3 | 5 | 3 | 8 | 0,90 | 5 | 0,10 | 20 | ✓ | 5,26 € |
| MPB3-8/B | M3 | 8 | 4 | 8 | 0,90 | 5 | 0,10 | 20 | ✓ | 5,71 € |
| MPB3-10/B | M3 | 10 | 6 | 8 | 0,90 | 5 | 0,10 | 20 | ✓ | 6,18 € |
| MPB3-12/B | M3 | 12 | 8 | 8 | 0,90 | 5 | 0,10 | 20 | - | 6,75 € |
| MPB3-15/B | M3 | 15 | 8 | 8 | 0,90 | 5 | 0,10 | 20 | ✓ | 7,49 € |
| MPB3-18/B | M3 | 18 | 8 | 8 | 0,90 | 5 | 0,10 | 20 | ✓ | 8,55 € |
| MPB3-20/B | M3 | 20 | 8 | 8 | 0,90 | 5 | 0,10 | 20 | ✓ | 9,29 € |
| MPB3-25/B | M3 | 25 | 10 | 10 | 0,90 | 5 | 0,10 | 20 | ✓ | 10,90 € |
| MPB3-30/B | M3 | 30 | 10 | 10 | 0,90 | 5 | 0,10 | 20 | ✓ | 12,72 € |
| MPB3-35/B | M3 | 35 | 10 | 10 | 0,90 | 5 | 0,10 | 20 | ✓ | 16,32 € |
| MPB3-40/B | M3 | 40 | 10 | 10 | 0,90 | 5 | 0,10 | 20 | - | 18,13 € |
| MPB3-45/B | M3 | 45 | 10 | 10 | 0,90 | 5 | 0,10 | 20 | ✓ | 20,13 € |
| MPB3-60/B | M3 | 60 | 10 | 10 | 0,90 | 5 | 0,10 | 20 | - | 20,01 € |
| MPB3-70/B | M3 | 70 | 10 | 10 | 0,90 | 5 | 0,10 | 20 | ✓ | 29,70 € |
| MPB4-8/B | M4 | 8 | 4 | 8 | 1,20 | 7 | 0,20 | 20 | ✓ | 8,94 € |
| MPB4-10/B | M4 | 10 | 6 | 8 | 1,20 | 7 | 0,20 | 20 | ✓ | 9,46 € |
| MPB4-12/B | M4 | 12 | 8 | 8 | 1,20 | 7 | 0,20 | 20 | ✓ | 10,00 € |
| MPB4-15/B | M4 | 15 | 8 | 8 | 1,20 | 7 | 0,20 | 20 | - | 11,30 € |
| MPB4-18/B | M4 | 18 | 8 | 8 | 1,20 | 7 | 0,20 | 20 | - | 12,73 € |
| MPB4-20/B | M4 | 20 | 8 | 8 | 1,20 | 7 | 0,20 | 20 | ✓ | 13,81 € |
| MPB4-25/B | M4 | 25 | 10 | 10 | 1,20 | 7 | 0,20 | 20 | ✓ | 16,15 € |
| MPB4-30/B | M4 | 30 | 10 | 10 | 1,20 | 7 | 0,20 | 20 | ✓ | 18,88 € |
| MPB4-35/B | M4 | 35 | 10 | 10 | 1,20 | 7 | 0,20 | 20 | - | 23,75 € |
| MPB4-45/B | M4 | 45 | 10 | 10 | 1,20 | 7 | 0,20 | 20 | ✓ | 29,51 € |
| MPB4-50/B | M4 | 50 | 10 | 10 | 1,20 | 7 | 0,20 | 20 | ✓ | 31,86 € |
| MPB4-80/B | M4 | 80 | 10 | 10 | 1,20 | 7 | 0,20 | 20 | ✓ | 49,02 € |
| MPB5-5/B | M5 | 5 | 3 | 8 | 1,40 | 8 | 0,20 | 20 | - | On request |
| MPB5-8/B | M5 | 8 | 4 | 8 | 1,40 | 8 | 0,20 | 20 | - | 12,05 € |
| MPB5-10/B | M5 | 10 | 6 | 8 | 1,40 | 8 | 0,20 | 20 | ✓ | 12,19 € |
| MPB5-12/B | M5 | 12 | 8 | 8 | 1,40 | 8 | 0,20 | 20 | ✓ | 13,28 € |
| MPB5-15/B | M5 | 15 | 8 | 8 | 1,40 | 8 | 0,20 | 20 | ✓ | 14,89 € |
| MPB5-20/B | M5 | 20 | 8 | 8 | 1,40 | 8 | 0,20 | 20 | - | 18,49 € |
| MPB5-25/B | M5 | 25 | 10 | 10 | 1,40 | 8 | 0,20 | 20 | - | 21,96 € |
| MPB5-30/B | M5 | 30 | 10 | 10 | 1,40 | 8 | 0,20 | 20 | ✓ | 26,83 € |
| MPB5-35/B | M5 | 35 | 10 | 10 | 1,40 | 8 | 0,20 | 20 | - | 29,85 € |
| MPB5-40/B | M5 | 40 | 10 | 10 | 1,40 | 8 | 0,20 | 20 | ✓ | 32,58 € |
| MPB5-50/B | M5 | 50 | 10 | 10 | 1,40 | 8 | 0,20 | 20 | - | 39,10 € |
| MPB5-60/B | M5 | 60 | 10 | 10 | 1,40 | 8 | 0,20 | 20 | ✓ | 46,68 € |
| MPB5-70/B | M5 | 70 | 10 | 10 | 1,40 | 8 | 0,20 | 20 | - | 52,62 € |
| MPB5-80/B | M5 | 80 | 10 | 10 | 1,40 | 8 | 0,20 | 20 | - | 60,76 € |

* Depending on availability - Dimensions in mm

Hexagonal spacer




HS

Stainless steel 303

- Female/female pillar
- Material:
stainless steel 303

Info.

- Sold by the packet

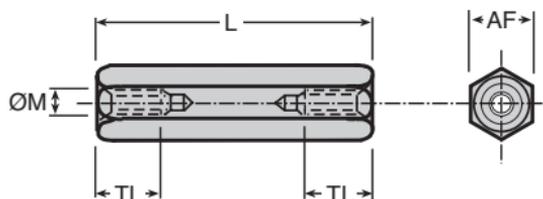

DISCOUNTS

| | | | | |
|------------|------|------|------|------------|
| N° packets | 1+ | 5+ | 20+ | 100+ |
| Discount | Prix | -20% | -30% | On request |


| Part number | Thread ØM | L | TL | AF | Qty per packet | Stock* | Price per packet |
|-------------|-----------|----|----|-----|----------------|--------|------------------|
| HS3-5/B | M3 | 5 | 5 | 5,5 | 20 | ✓ | 16,88 € |
| HS3-8/B | M3 | 8 | 8 | 5,5 | 20 | - | 17,98 € |
| HS3-10/B | M3 | 10 | 10 | 5,5 | 20 | ✓ | 18,45 € |
| HS3-15/B | M3 | 15 | 15 | 5,5 | 20 | ✓ | 22,69 € |
| HS3-20/B | M3 | 20 | 20 | 5,5 | 20 | ✓ | 28,45 € |
| HS3-25/B | M3 | 25 | 10 | 5,5 | 20 | - | 30,03 € |
| HS3-35/B | M3 | 35 | 10 | 5,5 | 20 | ✓ | 33,47 € |
| HS3-40/B | M3 | 40 | 10 | 5,5 | 20 | - | 34,34 € |
| HS4-5/B | M4 | 5 | 5 | 7,0 | 20 | - | 20,29 € |
| HS4-8/B | M4 | 8 | 8 | 7,0 | 20 | - | 22,14 € |
| HS4-10/B | M4 | 10 | 10 | 7,0 | 20 | ✓ | 24,33 € |
| HS4-12/B | M4 | 12 | 12 | 7,0 | 20 | ✓ | 26,21 € |
| HS4-15/B | M4 | 15 | 15 | 7,0 | 20 | - | 29,48 € |
| HS4-20/B | M4 | 20 | 20 | 7,0 | 20 | ✓ | 32,69 € |
| HS4-25/B | M4 | 25 | 10 | 7,0 | 20 | ✓ | 33,28 € |

*Depending on availability - Dimensions in mm

- Male/female pillar
- Material:
stainless steel 303

Info.

- Sold by the packet

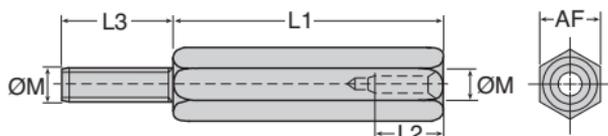**DISCOUNTS**

| N° packets | 1+ | 5+ | 20+ | 100+ |
|------------|------|------|------|------------|
| Discount | Prix | -20% | -30% | On request |

| Part number | Thread ØM | L1 | L2 | L3 | AF | Qty. per packet | Stock* | Price per packet |
|-------------|-----------|----|----|----|------|-----------------|--------|------------------|
| MPS3-5/B | M3 | 5 | 3 | 8 | 5,50 | 20 | ✓ | 24,26 € |
| MPS3-8/B | M3 | 8 | 4 | 8 | 5,50 | 20 | ✓ | 24,89 € |
| MPS3-10/B | M3 | 10 | 6 | 8 | 5,50 | 20 | ✓ | 25,34 € |
| MPS3-12/B | M3 | 12 | 8 | 8 | 5,50 | 20 | ✓ | 27,09 € |
| MPS3-15/B | M3 | 15 | 8 | 8 | 5,50 | 20 | ✓ | 27,75 € |
| MPS3-18/B | M3 | 18 | 8 | 8 | 5,50 | 20 | ✓ | 28,45 € |
| MPS3-20/B | M3 | 20 | 8 | 8 | 5,50 | 20 | ✓ | 28,83 € |
| MPS3-25/B | M3 | 25 | 10 | 10 | 5,50 | 20 | ✓ | 32,52 € |
| MPS4-5/B | M4 | 5 | 3 | 8 | 7,00 | 20 | ✓ | 25,29 € |
| MPS4-10/B | M4 | 10 | 6 | 8 | 7,00 | 20 | ✓ | 26,89 € |
| MPS4-15/B | M4 | 15 | 8 | 8 | 7,00 | 20 | ✓ | 29,81 € |
| MPS4-20/B | M4 | 20 | 8 | 8 | 7,00 | 20 | ✓ | 31,44 € |
| MPS4-25/B | M4 | 25 | 10 | 10 | 7,00 | 20 | ✓ | 35,79 € |

*Depending on availability - Dimensions in mm