



Hexagonal spacer

Stock **Ste**

MPE

Steel

- Male/female pillar
- Material: Zn3-5BL steel zinc-plated by electrolysis
- Sold by the packet

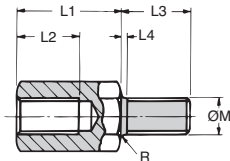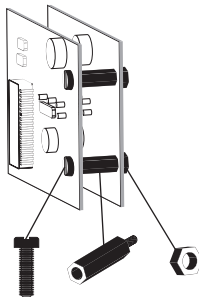

DISCOUNTS

N° packets	1+	5+	20+	100+
Discount	Prix -20%	-30%	On request	

Part number	Thread ØM	L1	L2	L3	L4	AF	R	Qty. per packet	Price per packet	
									Stock*	
MPE3-5/B	M3	5	3	8	0,90	5	0,10	20	✓	3,61 €
MPE3-8/B	M3	8	4	8	0,90	5	0,10	20	✓	4,61 €
MPE3-10/B	M3	10	6	8	0,90	5	0,10	20	✓	4,95 €
MPE3-12/B	M3	12	8	8	0,90	5	0,10	20	✓	5,01 €
MPE3-15/B	M3	15	8	8	0,90	5	0,10	20	✓	5,18 €
MPE3-18/B	M3	18	8	8	0,90	5	0,10	20	✓	5,34 €
MPE3-20/B	M3	20	8	8	0,90	5	0,10	20	✓	5,40 €
MPE3-25/B	M3	25	10	10	0,90	5	0,10	20	✓	6,21 €
MPE3-30/B	M3	30	10	10	0,90	5	0,10	20	✓	6,49 €
MPE3-35/B	M3	35	10	10	0,90	5	0,10	20	✓	6,78 €
MPE3-40/B	M3	40	10	10	0,90	5	0,10	20	✓	10,56 €
MPE3-45/B	M3	45	10	10	0,90	5	0,10	20	✓	11,46 €
MPE3-50/B	M3	50	10	10	0,90	5	0,10	20	✓	12,42 €
MPE3-55/B	M3	55	10	10	0,90	5	0,10	20	-	13,06 €
MPE3-60/B	M3	60	10	10	0,90	5	0,10	20	-	13,83 €
MPE3-70/B	M3	70	10	10	0,90	5	0,10	20	-	14,98 €
MPE3-80/B	M3	80	10	10	0,90	5	0,10	20	-	15,88 €
MPE4-5/B	M4	5	3	8	1,20	7	0,20	20	✓	5,79 €
MPE4-8/B	M4	8	4	8	1,20	7	0,20	20	✓	6,21 €
MPE4-10/B	M4	10	6	8	1,20	7	0,20	20	✓	5,76 €
MPE4-12/B	M4	12	8	8	1,20	7	0,20	20	✓	6,21 €
MPE4-15/B	M4	15	8	8	1,20	7	0,20	20	✓	6,27 €
MPE4-18/B	M4	18	8	8	1,20	7	0,20	20	-	6,84 €

*Depending on availability - Dimensions in mm

Part number	Thread ØM	L1	L2	L3	L4	AF	R	Qty. per packet	Stock*	Price per packet
MPE4-20/B	M4	20	8	8	1,20	7	0,20	20	✓	7,06 €
MPE4-25/B	M4	25	10	10	1,20	7	0,20	20	✓	8,29 €
MPE4-30/B	M4	30	10	10	1,20	7	0,20	20	✓	8,86 €
MPE4-35/B	M4	35	10	10	1,20	7	0,20	20	✓	9,41 €
MPE4-40/B	M4	40	10	10	1,20	7	0,20	20	✓	13,44 €
MPE4-45/B	M4	45	10	10	1,20	7	0,20	20	✓	13,44 €
MPE4-50/B	M4	50	10	10	1,20	7	0,20	20	-	15,20 €
MPE4-55/B	M4	55	10	10	1,20	7	0,20	20	-	16,16 €
MPE4-60/B	M4	60	10	10	1,20	7	0,20	20	✓	17,06 €
MPE4-70/B	M4	70	10	10	1,20	7	0,20	20	✓	19,30 €
MPE4-80/B	M4	80	10	10	1,20	7	0,20	20	✓	20,81 €
MPE5-5/B	M5	5	3	8	1,40	8	0,20	20	-	9,28 €
MPE5-8/B	M5	8	4	8	1,40	8	0,20	20	-	9,28 €
MPE5-10/B	M5	10	6	8	1,40	8	0,20	20	✓	9,28 €
MPE5-12/B	M5	12	8	8	1,40	8	0,20	20	✓	9,66 €
MPE5-15/B	M5	15	8	8	1,40	8	0,20	20	✓	10,11 €
MPE5-18/B	M5	18	8	8	1,40	8	0,20	20	-	10,62 €
MPE5-20/B	M5	20	8	8	1,40	8	0,20	20	✓	11,04 €
MPE5-25/B	M5	25	10	10	1,40	8	0,20	20	✓	11,97 €
MPE5-30/B	M5	30	10	10	1,40	8	0,20	20	✓	12,73 €
MPE5-35/B	M5	35	10	10	1,40	8	0,20	20	-	13,99 €
MPE5-40/B	M5	40	10	10	1,40	8	0,20	20	✓	15,23 €
MPE5-45/B	M5	45	10	10	1,40	8	0,20	20	✓	16,10 €
MPE5-50/B	M5	50	10	10	1,40	8	0,20	20	✓	17,03 €
MPE5-55/B	M5	55	10	10	1,40	8	0,20	20	-	17,96 €
MPE5-60/B	M5	60	10	10	1,40	8	0,20	20	✓	19,05 €
MPE5-70/B	M5	70	10	10	1,40	8	0,20	20	-	21,35 €
MPE5-80/B	M5	80	10	10	1,40	8	0,20	20	✓	24,97 €
MPE6-10/B	M6	10	6	12	2,10	10	0,25	20	✓	13,44 €
MPE6-12/B	M6	12	8	12	2,10	10	0,25	20	✓	13,54 €
MPE6-15/B	M6	15	8	12	2,10	10	0,25	20	✓	14,14 €
MPE6-18/B	M6	18	12	12	2,10	10	0,25	20	-	14,56 €
MPE6-20/B	M6	20	13	12	2,10	10	0,25	20	✓	15,07 €
MPE6-25/B	M6	25	13	12	2,10	10	0,25	20	✓	16,42 €
MPE6-30/B	M6	30	13	12	2,10	10	0,25	20	✓	17,19 €
MPE6-35/B	M6	35	13	12	2,10	10	0,25	20	✓	17,96 €
MPE6-40/B	M6	40	13	12	2,10	10	0,25	20	✓	18,76 €
MPE6-45/B	M6	45	13	12	2,10	10	0,25	20	✓	19,62 €
MPE6-50/B	M6	50	13	12	2,10	10	0,25	20	✓	20,71 €
MPE6-55/B	M6	55	13	12	2,10	10	0,25	20	-	21,52 €
MPE6-60/B	M6	60	13	12	2,10	10	0,25	20	✓	22,31 €
MPE6-70/B	M6	70	13	12	2,10	10	0,25	20	✓	24,23 €
MPE6-80/B	M6	80	13	12	2,10	10	0,25	20	✓	25,80 €

*Depending on availability - Dimensions in mm

Our other products



Miniature cam follower, Miniature



Worm and wheel set, Bronze



Hexagonal threaded sleeve, Hexagonal - steel



Parallel axis helical gear, Machined plastic (delrin)



Carabiner DIN5299 steel, Steel



Worm and wheel gear reducer, up to 980 Nm



Wheel - precision range, Bronze



Threaded spherical knob, Stainless steel 304



Wheel - precision range, Bronze



Linear ball slide - Stainless steel balls,



Ball transfer unit bolt fitting, Heavy



Stainless steel gas spring, Stainless steel

Complementary products



Hexagonal spacer, Steel



Hexagonal spacer, Brass