


Hexagonal spacer

Stock **Ste**

MPE

Steel

- Male/female pillar
- Material: Zn3-5BL steel zinc-plated by electrolysis
- Sold by the packet

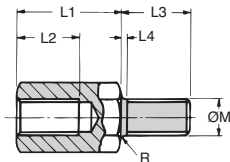

DISCOUNTS

N° packets	1+	5+	20+	100+
Discount	Prix -20%	-30%	On request	

Part number	Thread ØM	L1	L2	L3	L4	AF	R	Qty. per packet	Price per packet	
									Stock*	
MPE3-5/B	M3	5	3	8	0,90	5	0,10	20	✓	3,61 €
MPE3-8/B	M3	8	4	8	0,90	5	0,10	20	✓	4,61 €
MPE3-10/B	M3	10	6	8	0,90	5	0,10	20	✓	4,95 €
MPE3-12/B	M3	12	8	8	0,90	5	0,10	20	✓	5,01 €
MPE3-15/B	M3	15	8	8	0,90	5	0,10	20	✓	5,18 €
MPE3-18/B	M3	18	8	8	0,90	5	0,10	20	✓	5,34 €
MPE3-20/B	M3	20	8	8	0,90	5	0,10	20	✓	5,40 €
MPE3-25/B	M3	25	10	10	0,90	5	0,10	20	✓	6,21 €
MPE3-30/B	M3	30	10	10	0,90	5	0,10	20	✓	6,49 €
MPE3-35/B	M3	35	10	10	0,90	5	0,10	20	✓	6,78 €
MPE3-40/B	M3	40	10	10	0,90	5	0,10	20	✓	10,56 €
MPE3-45/B	M3	45	10	10	0,90	5	0,10	20	✓	11,46 €
MPE3-50/B	M3	50	10	10	0,90	5	0,10	20	✓	12,42 €
MPE3-55/B	M3	55	10	10	0,90	5	0,10	20	-	13,06 €
MPE3-60/B	M3	60	10	10	0,90	5	0,10	20	-	13,83 €
MPE3-70/B	M3	70	10	10	0,90	5	0,10	20	-	14,98 €
MPE3-80/B	M3	80	10	10	0,90	5	0,10	20	-	15,88 €
MPE4-5/B	M4	5	3	8	1,20	7	0,20	20	✓	5,79 €
MPE4-8/B	M4	8	4	8	1,20	7	0,20	20	✓	6,21 €
MPE4-10/B	M4	10	6	8	1,20	7	0,20	20	✓	5,76 €
MPE4-12/B	M4	12	8	8	1,20	7	0,20	20	✓	6,21 €
MPE4-15/B	M4	15	8	8	1,20	7	0,20	20	✓	6,27 €
MPE4-18/B	M4	18	8	8	1,20	7	0,20	20	-	6,84 €

*Depending on availability - Dimensions in mm

Part number	Thread ØM	L1	L2	L3	L4	AF	R	Qty. per packet	Stock*	Price per packet
MPE4-20/B	M4	20	8	8	1,20	7	0,20	20	✓	7,06 €
MPE4-25/B	M4	25	10	10	1,20	7	0,20	20	✓	8,29 €
MPE4-30/B	M4	30	10	10	1,20	7	0,20	20	✓	8,86 €
MPE4-35/B	M4	35	10	10	1,20	7	0,20	20	✓	9,41 €
MPE4-40/B	M4	40	10	10	1,20	7	0,20	20	✓	13,44 €
MPE4-45/B	M4	45	10	10	1,20	7	0,20	20	✓	13,44 €
MPE4-50/B	M4	50	10	10	1,20	7	0,20	20	-	15,20 €
MPE4-55/B	M4	55	10	10	1,20	7	0,20	20	-	16,16 €
MPE4-60/B	M4	60	10	10	1,20	7	0,20	20	✓	17,06 €
MPE4-70/B	M4	70	10	10	1,20	7	0,20	20	✓	19,30 €
MPE4-80/B	M4	80	10	10	1,20	7	0,20	20	✓	20,81 €
MPE5-5/B	M5	5	3	8	1,40	8	0,20	20	-	9,28 €
MPE5-8/B	M5	8	4	8	1,40	8	0,20	20	-	9,28 €
MPE5-10/B	M5	10	6	8	1,40	8	0,20	20	✓	9,28 €
MPE5-12/B	M5	12	8	8	1,40	8	0,20	20	✓	9,66 €
MPE5-15/B	M5	15	8	8	1,40	8	0,20	20	✓	10,11 €
MPE5-18/B	M5	18	8	8	1,40	8	0,20	20	-	10,62 €
MPE5-20/B	M5	20	8	8	1,40	8	0,20	20	✓	11,04 €
MPE5-25/B	M5	25	10	10	1,40	8	0,20	20	✓	11,97 €
MPE5-30/B	M5	30	10	10	1,40	8	0,20	20	✓	12,73 €
MPE5-35/B	M5	35	10	10	1,40	8	0,20	20	-	13,99 €
MPE5-40/B	M5	40	10	10	1,40	8	0,20	20	✓	15,23 €
MPE5-45/B	M5	45	10	10	1,40	8	0,20	20	✓	16,10 €
MPE5-50/B	M5	50	10	10	1,40	8	0,20	20	✓	17,03 €
MPE5-55/B	M5	55	10	10	1,40	8	0,20	20	-	17,96 €
MPE5-60/B	M5	60	10	10	1,40	8	0,20	20	✓	19,05 €
MPE5-70/B	M5	70	10	10	1,40	8	0,20	20	-	21,35 €
MPE5-80/B	M5	80	10	10	1,40	8	0,20	20	✓	24,97 €
MPE6-10/B	M6	10	6	12	2,10	10	0,25	20	✓	13,44 €
MPE6-12/B	M6	12	8	12	2,10	10	0,25	20	✓	13,54 €
MPE6-15/B	M6	15	8	12	2,10	10	0,25	20	✓	14,14 €
MPE6-18/B	M6	18	12	12	2,10	10	0,25	20	-	14,56 €
MPE6-20/B	M6	20	13	12	2,10	10	0,25	20	✓	15,07 €
MPE6-25/B	M6	25	13	12	2,10	10	0,25	20	✓	16,42 €
MPE6-30/B	M6	30	13	12	2,10	10	0,25	20	✓	17,19 €
MPE6-35/B	M6	35	13	12	2,10	10	0,25	20	✓	17,96 €
MPE6-40/B	M6	40	13	12	2,10	10	0,25	20	✓	18,76 €
MPE6-45/B	M6	45	13	12	2,10	10	0,25	20	✓	19,62 €
MPE6-50/B	M6	50	13	12	2,10	10	0,25	20	✓	20,71 €
MPE6-55/B	M6	55	13	12	2,10	10	0,25	20	-	21,52 €
MPE6-60/B	M6	60	13	12	2,10	10	0,25	20	✓	22,31 €
MPE6-70/B	M6	70	13	12	2,10	10	0,25	20	✓	24,23 €
MPE6-80/B	M6	80	13	12	2,10	10	0,25	20	✓	25,80 €

*Depending on availability - Dimensions in mm

Our other products



RTT

Locking Assembly,
Medium/high torque




PTAF80-PAMF80

Articulated fixable
foot with pressed
base Ø80, Ø 80



DZYSS

 Stainless steel
cylindrical stop,
stainless steel



MLY

Bow shackle with eye
bolt, Steel



CHM75

Worm and wheel gear
reducer, up to 298
Nm



BDM

Pin for magnetic bush,
Fast and light
magnetic locking



IBJss

Ball and socket joint,
Stainless steel




RURp

Fixed castor with
plate, Polyurethane -
Aluminium rim (Free
running)



NK27

 Drylin®N miniature
guiding system, Width



TR

Spur round rack,
Stainless steel -



TBbutee

Axial thrust bearing,
Steel balls



PFL

P-FLEX Coupling, Set
screw

Complementary products



HSE-HSB

Hexagonal spacer,
Steel



MPB

Hexagonal spacer,
Brass