


- For joining or closing chains
- Screw to secure
- Fully tighten to ensure safety
- Material:

Stainless steel 316

Ring/nut X2CrNi

Info.

- SWL: safe working load.
- The Safe Working Load is calculated by dividing the Breaking Strength by a factor of safety of 3.

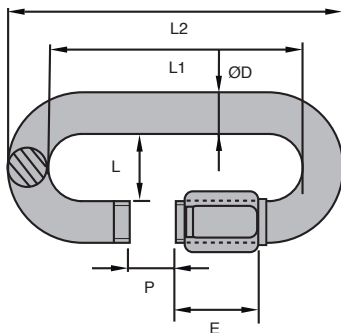

DISCOUNTS

Qty	1+	5+	10+	20+	30+
Disc.	List	-5%	-10%	-15%	On request

Part number	ØD	L2	L1	L	P	E	SWL (kg)	Weight for 100 pieces (kg)	Stock*	Price each 1 to 4
MRA1-04/SS	4	40,0	32,0	11,0	6,0	12,0	280	1,200	✓	8,64 €
MRA1-05/SS	5	48,0	38,0	12,0	7,0	16,0	450	2,100	✓	9,65 €
MRA1-06/SS	6	57,0	45,0	14,0	9,0	19,0	650	3,540	✓	12,32 €
MRA1-07/SS	7	66,0	52,0	16,0	8,0	21,0	900	5,230	-	16,76 €
MRA1-08/SS	8	73,0	57,0	17,0	12,0	24,0	1100	7,900	-	16,76 €
MRA1-09/SS	9	80,0	62,0	19,0	11,0	26,0	1400	10,500	-	25,33 €
MRA1-10/SS	10	89,0	69,0	20,0	13,0	29,0	1800	14,050	-	30,66 €
MRA1-12/SS	12	105,0	81,0	23,0	16,0	34,0	2500	23,200	✓	48,83 €

*Depending on availability - Dimensions in mm

Our other products



SRG
Adjustable latch
clamp with strike
plate, Stroke from
77,3mm to 83mm



UCF
Cast iron flange
bearing unit, Cast iron



EBC
Cap nut Hygienic
Design®, Compact



HLA19
Right angle spiro
bevel gearbox, Up to
43Nm



PGNT
Thermoplastic T
handle, With threaded
insert



PSG125S
Spur gear - precision
range, Stainless steel
316



RAG
Roller guide,



CLM
Male clevis end,
Stainless steel short



PF30
Worm and wheel gear
reducer, up to 8.80
Nm



PAL
Self locking counter
nut, For axial locking



GSI_A
Gas control screw for
gas spring, Gas
control screw



BPM
Slotted spring plunger
with ball tip, Stainless
steel 303

Complementary products



CHN_CHNSS
Straight long link
stainless steel chain,
Stainless steel



MRASSeco
Low cost stainless
steel quick link,
Stainless steel



MRAeco
Low cost quick link,
Steel



MRA
Quick link, Steel