


- For joining or closing chains
- Screw to secure
- Fully tighten to ensure safety
- Material:

Stainless steel 316

Ring/nut X2CrNi

Info.

- SWL: safe working load.
- The Safe Working Load is calculated by dividing the Breaking Strength by a factor of safety of 3.

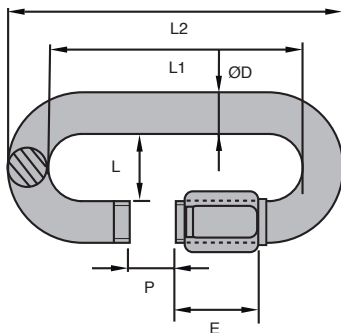

DISCOUNTS

Qty	1+	5+	10+	20+	30+
Disc.	List	-5%	-10%	-15%	On request

Part number	ØD	L2	L1	L	P	E	SWL (kg)	Weight for 100 pieces (kg)	Stock*	Price each 1 to 4
MRA1-04/SS	4	40,0	32,0	11,0	6,0	12,0	280	1,200	✓	8,64 €
MRA1-05/SS	5	48,0	38,0	12,0	7,0	16,0	450	2,100	✓	9,65 €
MRA1-06/SS	6	57,0	45,0	14,0	9,0	19,0	650	3,540	✓	12,32 €
MRA1-07/SS	7	66,0	52,0	16,0	8,0	21,0	900	5,230	-	16,76 €
MRA1-08/SS	8	73,0	57,0	17,0	12,0	24,0	1100	7,900	-	16,76 €
MRA1-09/SS	9	80,0	62,0	19,0	11,0	26,0	1400	10,500	-	25,33 €
MRA1-10/SS	10	89,0	69,0	20,0	13,0	29,0	1800	14,050	-	30,66 €
MRA1-12/SS	12	105,0	81,0	23,0	16,0	34,0	2500	23,200	✓	48,83 €

*Depending on availability - Dimensions in mm

Our other products



ESCON

Speed controller 5A accessories, Kit of 4 cables for DC motor



SH2

Parallel axis helical gear, Steel 20NCD2



BLHB30

Right angled gearbox, bored shafts, up to 4.4 Nm



SH1

Parallel axis helical gear, Steel 20NCD2



DFG

Flat suction cup, nitrile



PT882

Drive sprocket for slat top chain, Range 882



 
MHXred

Reducing sleeve male/female, Hexagonal - stainless steel



ZDB

Machined plastic bevel gear, 2:1



H0

Crossed helical gear crossed axis at 90°, Machined plastic



RPB

Ballscrew bearing unit, Support



BLM

Spring loaded plunger with ball tip, Stainless steel body



PCF4

Conical flexible mount, Square base plate

Complementary products



CHN_CHNSS

Straight long link stainless steel chain, Stainless steel




MRASSeco

Low cost stainless steel quick link, Stainless steel



MRAeco

Low cost quick link, Steel

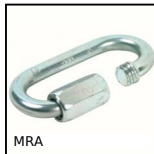

MRA

Quick link, Steel