


- For joining or closing chains
- Screw to secure
- Fully tighten to ensure safety
- Material:

Stainless steel 316

Ring/nut X2CrNi

### Info.

- SWL: safe working load.
- The Safe Working Load is calculated by dividing the Breaking Strength by a factor of safety of 3.

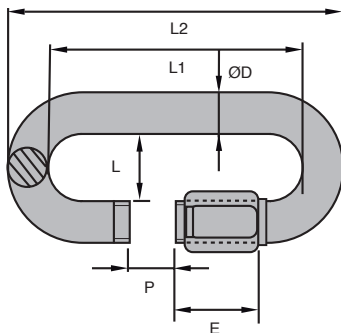

### DISCOUNTS

Qty	1+	5+	10+	20+	30+
Disc. List	-5%	-10%	-15%	On request	

Part number	ØD	L2	L1	L	P	E	SWL (kg)	Weight for 100 pieces (kg)	Stock*	Price each 1 to 4
MRA1-04/SS	4	40,0	32,0	11,0	6,0	12,0	280	1,200	✓	8,64 €
MRA1-05/SS	5	48,0	38,0	12,0	7,0	16,0	450	2,100	✓	9,65 €
MRA1-06/SS	6	57,0	45,0	14,0	9,0	19,0	650	3,540	✓	12,32 €
MRA1-07/SS	7	66,0	52,0	16,0	8,0	21,0	900	5,230	-	16,76 €
MRA1-08/SS	8	73,0	57,0	17,0	12,0	24,0	1100	7,900	-	16,76 €
MRA1-09/SS	9	80,0	62,0	19,0	11,0	26,0	1400	10,500	-	25,33 €
MRA1-10/SS	10	89,0	69,0	20,0	13,0	29,0	1800	14,050	-	30,66 €
MRA1-12/SS	12	105,0	81,0	23,0	16,0	34,0	2500	23,200	✓	48,83 €

\*Depending on availability - Dimensions in mm

## Our other products



HBM

Adjustment bushing for half-rail guide, Adjustment bushing



SH3

Parallel axis helical gear, Machined plastic (delrin)



BTC20\_10

End cap for rectangular tube, Standard



PRF\_BM

Base support plate for aluminium profile, Central base fixation



PRES3HR

Manual workbench press, Force up to 400kg



EKN

Bellows coupling Gerwah®, from 0.5 to 12Nm



PAS

Pull handle, Reinforced PA thermoplastic



CHARcav

Spring hinge, to install



LRM

Trapezoidal bronze nut, Bronze - 1 thread



VRM

Female swivelling lifting rings, Female swivelling



DIV\_SS

Stainless steel locking bolt, With grip - Stainless steel



PTRSS

Idler chain sprocket, For hostile environments

## Complementary products



CHN\_CHNSS

Straight long link stainless steel chain, Stainless steel



MRASSeco

Low cost stainless steel quick link, Stainless steel



PPCcs

Pad eye on mounting plate squarred, Stainless steel