

- For joining or closing chains

- Screw to secure

- Fully tighten to ensure safety

- Material:

Stainless steel 316


Ring/nut X2CrNi

Info.

- SWL: safe working load.

The Safe Working Load is calculated by dividing the Breaking Strength by a factor of safety of 3.

stainless steel

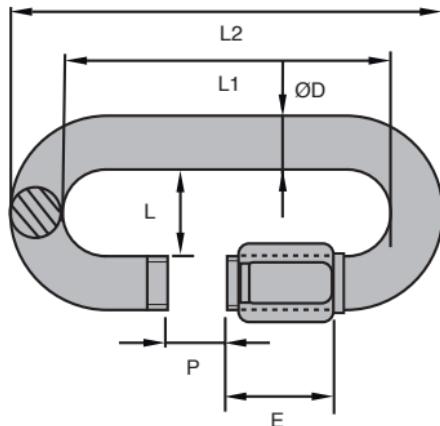

DISCOUNTS

Qty	1+	5+	10+	20+	30+
Disc. List	-5%	-10%	-15%	On request	

Part number	ØD	L2	L1	L	P	E	SWL (kg)	Weight for 100 pieces (kg)	Stock*	Price each
MRA1-04/SS	4	40,0	32,0	11,0	6,0	12,0	280	1,200	✓	8,64 €
MRA1-05/SS	5	48,0	38,0	12,0	7,0	16,0	450	2,100	✓	9,65 €
MRA1-06/SS	6	57,0	45,0	14,0	9,0	19,0	650	3,540	✓	12,32 €
MRA1-07/SS	7	66,0	52,0	16,0	8,0	21,0	900	5,230	-	16,76 €
MRA1-08/SS	8	73,0	57,0	17,0	12,0	24,0	1100	7,900	-	16,76 €
MRA1-09/SS	9	80,0	62,0	19,0	11,0	26,0	1400	10,500	-	25,33 €
MRA1-10/SS	10	89,0	69,0	20,0	13,0	29,0	1800	14,050	-	30,66 €
MRA1-12/SS	12	105,0	81,0	23,0	16,0	34,0	2500	23,200	✓	48,83 €

*Depending on availability - Dimensions in mm

Our other products



T5M T10M



ABL100005



GE_ES



CHM30

T type timing belt per metre, T5 Steel cored polyurethane

Antistatic brush, Standard

Spherical bushing, Steel / steel

Worm and wheel gear reducer, up to 28 Nm



UGH25

H Type Guide units, For Ø25 actuators



E60B

Right angle helical reducers, from 4.50 to 24 Nm



BIMSS

Indexing plunger mini, miniature - Stainless steel




RIMple

Locking castor, with mounting plate



RURp

Swivel castor with double brake, Polyurethane -

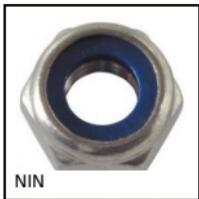

NIN

Self-locking nut, Steel



RLX

Free running conveyor roller, PVC



PP50

Worm and wheel gear reducer, from 6.50 to 12.80 Nm

Complementary products




Straight long link stainless steel chain, Stainless steel



Low cost stainless steel quick link, Stainless steel



Low cost quick link, Steel

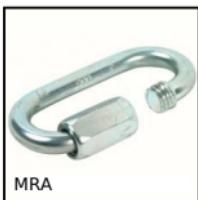

Quick link, Steel