


- For joining or closing chains
- Screw to secure
- Fully tighten to ensure safety
- Material:

Stainless steel 316

Ring/nut X2CrNi

Info.

- SWL: safe working load.
- The Safe Working Load is calculated by dividing the Breaking Strength by a factor of safety of 3.

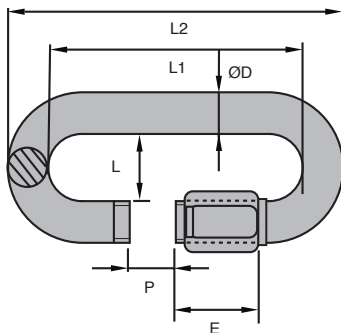

DISCOUNTS

Qty	1+	5+	10+	20+	30+
Disc. List	-5%	-10%	-15%	On request	

Part number	ØD	L2	L1	L	P	E	SWL (kg)	Weight for 100 pieces (kg)	Stock*	Price each 1 to 4
MRA1-04/SS	4	40,0	32,0	11,0	6,0	12,0	280	1,200	✓	8,64 €
MRA1-05/SS	5	48,0	38,0	12,0	7,0	16,0	450	2,100	✓	9,65 €
MRA1-06/SS	6	57,0	45,0	14,0	9,0	19,0	650	3,540	✓	12,32 €
MRA1-07/SS	7	66,0	52,0	16,0	8,0	21,0	900	5,230	-	16,76 €
MRA1-08/SS	8	73,0	57,0	17,0	12,0	24,0	1100	7,900	-	16,76 €
MRA1-09/SS	9	80,0	62,0	19,0	11,0	26,0	1400	10,500	-	25,33 €
MRA1-10/SS	10	89,0	69,0	20,0	13,0	29,0	1800	14,050	-	30,66 €
MRA1-12/SS	12	105,0	81,0	23,0	16,0	34,0	2500	23,200	✓	48,83 €

*Depending on availability - Dimensions in mm

Our other products



 
GE_ET_2RS

Spherical bushing,
Hard chromium /
Teflon contact with
seals



J66

Spur gear coaxial
gearbox, from 0.90 to
2.80 Nm - In-line




M0

Worm and wheel set,
Machined plastic
(delrin)



KK

 Rounded end feather
key, Steel



T5courroie

T type timing belt, T5
Steel cored
polyurethane



YG3

HEAVY DUTY spur
gear, Steel 35NCD6



TCSH

Automatic chain
tensioner, With
support



CHAL3

Piano hinge,
Aluminium



BPFss

Pressed stainless
steel flange bearing,



BOXKK

Boxed set of
DIN6885A keys,



SLH-M

Nut for toggle clamp,
Round ended nut for



VTH

Hexagonal headed
bolts, Steel class 8.8

Complementary products



CHN_CHNSS

Straight long link
stainless steel chain,
Stainless steel



MRASSeco

Low cost stainless
steel quick link,
Stainless steel



MRAeco

Low cost quick link,
Steel



MRA

Quick link, Steel