


- For joining or closing chains
- Screw to secure
- Fully tighten to ensure safety
- Material:

Stainless steel 316

Ring/nut X2CrNi

Info.

- SWL: safe working load.
- The Safe Working Load is calculated by dividing the Breaking Strength by a factor of safety of 3.

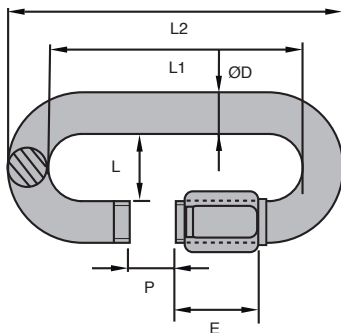

DISCOUNTS

Qty	1+	5+	10+	20+	30+
Disc.	List	-5%	-10%	-15%	On request

Part number	ØD	L2	L1	L	P	E	SWL (kg)	Weight for 100 pieces (kg)	Stock*	Price each 1 to 4
MRA1-04/SS	4	40,0	32,0	11,0	6,0	12,0	280	1,200	✓	8,64 €
MRA1-05/SS	5	48,0	38,0	12,0	7,0	16,0	450	2,100	✓	9,65 €
MRA1-06/SS	6	57,0	45,0	14,0	9,0	19,0	650	3,540	✓	12,32 €
MRA1-07/SS	7	66,0	52,0	16,0	8,0	21,0	900	5,230	-	16,76 €
MRA1-08/SS	8	73,0	57,0	17,0	12,0	24,0	1100	7,900	-	16,76 €
MRA1-09/SS	9	80,0	62,0	19,0	11,0	26,0	1400	10,500	-	25,33 €
MRA1-10/SS	10	89,0	69,0	20,0	13,0	29,0	1800	14,050	-	30,66 €
MRA1-12/SS	12	105,0	81,0	23,0	16,0	34,0	2500	23,200	✓	48,83 €

*Depending on availability - Dimensions in mm

Our other products



RFV40
Stainless steel worm and wheel gearbox, up to 47 Nm



UGH20
H Type Guide units, For Ø20 actuators



BOX-TOR-B
Box set of Nitrile O-rings in nitrile, 20.38 x 1.78mm to 50.16 x 5.34



SLHVlok
Horizontal toggle clamp, Horizontal toggle clamp / vertical foot



BABFCFO
Ball pin socket, Mounting collar with a oval flange



ATZYSS
Stainless steel diablo shaped elasto mount, Stainless steel



PGMT
Pull handle, Steel



AT5P_AT10P
Connecting plate for AT type timing belts, AT10



CHA35
Hinge for aluminium profile, Hinge



PTA50
Articulated levelling foot, pressed base



PRF19_E
Bracket for aluminium profile, PRF19 to



HLUs
Spoked handwheel, Stainless steel 316

Complementary products




CHN_CHNSS
Straight long link stainless steel chain, Stainless steel



MRASSeco
Low cost stainless steel quick link, Stainless steel



MRAeco
Low cost quick link, Steel

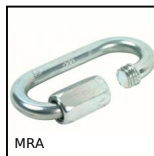

MRA
Quick link, Steel