


- For joining or closing chains
- Screw to secure
- Fully tighten to ensure safety CE and SWL markings
- Material:  
Link : Steel Fe430B zinc treated  
Nut: Steel A-42-Fm

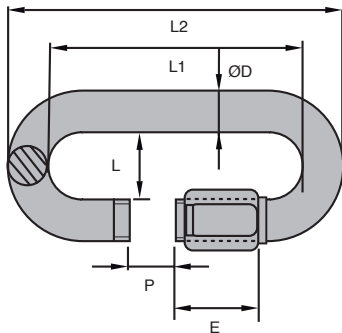

### Info.

- SWL: safe working load.  
The Safe Working Load is calculated by dividing the Breaking Strength by a factor of safety of 5.
- Not sold individually, please contact us for details



### DISCOUNTS

Qty	1+	10+	20+	30+	50+
Disc.	List	-5%	-10%	-15%	On request

Part number	ØD	L2	L1	L	P	E	SWL (kg)	Weight for 100 pieces (kg)	Stock*	Price each 1 to 9
MRA1-04	4	39,5	31,5	11,5	5,5	12,5	180	1,170	✓	2,60 €
MRA1-05	5	49,5	39,5	13,0	6,5	16,0	280	2,050	✓	2,96 €
MRA1-06	6	57,0	45,0	14,5	7,5	19,0	400	3,450	✓	3,49 €
MRA1-07	7	66,0	52,0	16,0	8,5	21,5	550	5,100	✓	4,40 €
MRA1-08	8	74,0	58,0	17,5	11,0	24,0	700	7,700	✓	5,06 €
MRA1-09	9	80,0	62,0	19,0	11,0	26,0	900	10,250	✓	6,83 €
MRA1-10	10	89,0	69,0	20,5	12,0	29,0	1100	13,700	✓	7,58 €
MRA1-12	12	104,5	80,5	23,5	15,0	33,0	1500	23,200	✓	10,97 €

\*Depending on availability - Dimensions in mm

## Our other products




GLB  
Small 6 lobe threaded handle,  
Technopolymer -  
Stainless steel



MSP38  
Masterplate®  
glueable insert,  
Cylindrical Ø38 with  
threaded stud



SH2  
Parallel axis helical  
gear, Steel 20NCD2

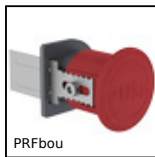

PRFbou  
Closing system,  
Emergency release  
button



BPHclip  
Ball transfer unit,  
Insert clip - Installing  
from above



MAC  
Carabiner, Steel



BOX-INS-W  
Self tapping insert,  
Boxed set - For wood



PXHG2  
Crossed helical gear -  
precision range,  
35NCD6 Pre-hardened  
steel



CQA20  
Adjustment slide-  
system miniature, 20



SLBE  
Index bolt, Spacer for  
SLB and SLBS index  
bolts



DOMI50  
DOMILINE -  
Accessories, XY  
linking kit



TBL  
Mini leadscrew table  
with metric thread,  
For manual position  
adjustment

## Complementary products



CHN\_CHNSS  
Straight long link  
chain, Galvanised  
steel



MRAeco  
Quick link, Steel



CHNrb  
Warning chain with  
red and white links,  
Steel