

- For joining or closing chains
- Stainless steel 316
- Low cost range, no SWL specified

Application


- Nominal load figures are given as an indication only
- Should not be used for lifting (load values not guaranteed)

Info

- Also available in steel



Economy range

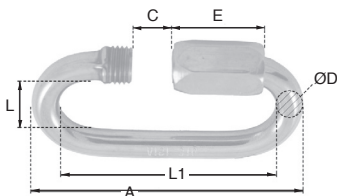

DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØD	A	L1	L	C	E	Nominal load (kg)	Weight (g)	Stock*	Price each
										1 to 19
MRA1-03/SS/ECO	3,5	37,2	30,4	9,7	5,5	12,6	220	8	✓	3,58 €
MRA1-04/SS/ECO	4,0	41,0	33,0	11,7	6,3	12,7	280	12	✓	3,89 €
MRA1-05/SS/ECO	5,0	51,2	41,0	13,0	7,0	17,0	450	22	✓	4,40 €
MRA1-06/SS/ECO	6,0	59,0	47,0	14,7	8,8	20,0	650	36	✓	4,98 €
MRA1-07/SS/ECO	7,0	67,7	54,0	18,3	9,7	23,7	900	54	-	8,53 €
MRA1-08/SS/ECO	8,0	74,6	59,0	18,3	9,9	25,0	1100	76	✓	9,99 €
MRA1-10/SS/ECO	10,0	89,0	70,0	22,2	12,8	30,0	1800	138	-	17,28 €
MRA1-12/SS/ECO	12,0	105,0	82,0	24,8	14,2	34,0	3500	224	-	27,66 €

*Depending on availability - Dimensions in mm

Our other products



EPE

Wing nuts Hygienic Design®, Narrow



PCS6ECO

Chain sprocket - steel, 6mm (DIN 04-1)



LBE

Miniature closed linear bearing, Miniature



RURp

Wheel pivoting with plate, Polyurethane - Aluminium rim (Free running)



SMS

Spiral bevel gear, 1:1



CHA_GC_9SS

Stainless steel garnet hinge, To be welded



CHT

Asynchronous AC motor , 0.09kW




SVR5

Screwjack with travelling nut, with moving nut



UCP_SS

 Stainless steel pillow block bearing, Stainless steel



RPPM

RPP type belt per metre, RPP5 Steel cored polyurethane



HTD5M_15

HTD Heavy duty timing pulley, HTD5 Steel



NKX

Combined bearing without inner ring, Needle and ball bearings

Complementary products



CHN_CHNSS

Straight long link stainless steel chain, Stainless steel



MRA_SS

Stainless steel Quick link, Stainless steel



PPRss

Pad eye on mounting plate round, Stainless steel