

- For joining or closing chains
- Stainless steel 316
- Low cost range, no SWL specified

Application


- Nominal load figures are given as an indication only
- Should not be used for lifting (load values not guaranteed)

Info

- Also available in steel



Economy range

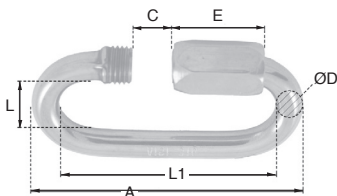

DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØD	A	L1	L	C	E	Nominal load (kg)	Weight (g)	Stock*	Price each
										1 to 19
MRA1-03/SS/ECO	3,5	37,2	30,4	9,7	5,5	12,6	220	8	✓	3,58 €
MRA1-04/SS/ECO	4,0	41,0	33,0	11,7	6,3	12,7	280	12	✓	3,89 €
MRA1-05/SS/ECO	5,0	51,2	41,0	13,0	7,0	17,0	450	22	✓	4,40 €
MRA1-06/SS/ECO	6,0	59,0	47,0	14,7	8,8	20,0	650	36	✓	4,98 €
MRA1-07/SS/ECO	7,0	67,7	54,0	18,3	9,7	23,7	900	54	-	8,53 €
MRA1-08/SS/ECO	8,0	74,6	59,0	18,3	9,9	25,0	1100	76	✓	9,99 €
MRA1-10/SS/ECO	10,0	89,0	70,0	22,2	12,8	30,0	1800	138	-	17,28 €
MRA1-12/SS/ECO	12,0	105,0	82,0	24,8	14,2	34,0	3500	224	-	27,66 €

*Depending on availability - Dimensions in mm

Our other products



DOMI30
Accessories, Turntable



GBS
Nut for ballscrew,
Flanged ballscrew nut



GCL
Linear ball slide -
Stainless steel balls,
Chariot - from 516 N
to 8...



COA-COG
Surface mounting
plate, Surface
mounting plate for
clevis



WS16
Dylin® W rail, Rail




GGB
Female wing knob,
With blind thread



DKGS
Backlash free
coupling Gerwah®,
from 0.5 to 3Nm



 DGS1
Female rod ends,
Steel / steel -
Economy range



QNJ
Single row cylindrical
roller bearing, Single
flange on inner ring



PSG08S
Spur gear - precision
range, Stainless steel
303



CHA138
Screwed hinge with
threaded insert, 138
degrees



PAT123
Pressed stainless
steel articulating foot
Ø123, Ø 123

Complementary products



CHN_CHNSS
Straight long link
stainless steel chain,
Stainless steel



MRA_SS
Stainless steel Quick
link, Stainless steel



PPRss
Pad eye on mounting
plate round, Stainless
steel