

- For joining or closing chains
- Stainless steel 316
- Low cost range, no SWL specified

Application


- Nominal load figures are given as an indication only
- Should not be used for lifting (load values not guaranteed)

Info

- Also available in steel



Economy range

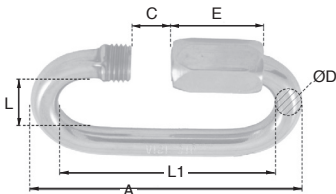

DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØD	A	L1	L	C	E	Nominal load (kg)	Weight (g)	Stock*	Price each 1 to 19
MRA1-03/SS/ECO	3,5	37,2	30,4	9,7	5,5	12,6	220	8	✓	3,58 €
MRA1-04/SS/ECO	4,0	41,0	33,0	11,7	6,3	12,7	280	12	✓	3,89 €
MRA1-05/SS/ECO	5,0	51,2	41,0	13,0	7,0	17,0	450	22	✓	4,40 €
MRA1-06/SS/ECO	6,0	59,0	47,0	14,7	8,8	20,0	650	36	✓	4,98 €
MRA1-07/SS/ECO	7,0	67,7	54,0	18,3	9,7	23,7	900	54	-	8,53 €
MRA1-08/SS/ECO	8,0	74,6	59,0	18,3	9,9	25,0	1100	76	✓	9,99 €
MRA1-10/SS/ECO	10,0	89,0	70,0	22,2	12,8	30,0	1800	138	-	17,28 €
MRA1-12/SS/ECO	12,0	105,0	82,0	24,8	14,2	34,0	3500	224	-	27,66 €

*Depending on availability - Dimensions in mm

Our other products




ACLBTS

Spherical ended stop for aluminium profile, Spherical ended stop



BPVMss

Stainless steel miniature ball transfer unit, Miniature to screw

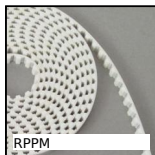

RPPM

RPP type belt per metre, RPP14 Steel cored polyurethane



SCR

Suction cup threaded insert, Adaptator for insert




G4

Steel spur gear, Steel 20NCD2



PTA80

 Articulated levelling foot, pressed base Ø80, Ø 80



KS

Keysteel, Steel - Keystock



SER

Magnetic doorstop for aluminium profile, Magnetic doorstop



RLR

Roll-Ring® chain tensioner, Roll-Ring®




TBD

Manual leadscrew table with opposing



AT10-25ECO

 AT type timing pulley, Economy range -



ZR

Plastic rack, Delrin

Complementary products



CHN_CHNSS

Straight long link stainless steel chain, Stainless steel



MRA_SS

Stainless steel Quick link, Stainless steel



MRAeco

Low cost quick link, Steel



MRA

Quick link, Steel